



50 Amp Twist-Lock[®] Devices

50A Twist-Lock® Devices

Hubbell's 50 Amp Twist-Lock® Devices feature a heavy-duty design and super-tough nylon housing built for heavy-duty applications and impact resistance, even in the harshest environments. Their rigid construction restricts contact distortion, minimizing the possibility of mating dissimilar devices. The cord grip's offset gripping jaws securely hold the conductors and the cord jacket for excellent strain relief.

- » *Support secure, reliable, superior terminations with Hubbell's box terminals*
- » *Ensure durability with solid, stainless steel shrouds on plugs*
- » *Achieve high heat resistance on receptacles and inlets with thermoset interior components*

Ideal for:



Ordering Information

50A Twist-Lock® Devices

Description	Cord Diameter	Rating	Catalog Number			
Plugs	Nylon housing, thermoplastic polyester interior .830"-1.250" (21.08-31.75)	50A 125V AC	CS6361C			
		50A 250V AC	CS8265C			
		50A 480V AC	CS8465C			
		50A 125/250V AC	CS6365C			
		50A 3Ø 250V AC	CS8365C			
		50A 3Ø 480V AC	CS8165C			
Connector body	Nylon housing, thermoplastic polyester interior .830"-1.250" (21.08-31.75)	50A 125V AC	CS6360C			
		50A 250V AC	CS8264C			
		50A 480V AC	CS8464C			
		50A 125/250V AC	CS6364C			
		50A 3Ø 250V AC	CS8364C			
		50A 3Ø 480V AC	CS8164C			
Insulgrip® connector with conduit adapter; capable of accepting metallic or non-metallic conduit fittings	½" NPT size ¾" NPT size 1" NPT size	50A 3Ø 250V AC	CS8364CA05 CS8364CA34 CS8364CA10			
		Flanged inlet	Zinc plated steel casing, thermoset interior	—	50A 125V AC	CS6377
					50A 250V AC	CS8275
50A 480V AC	CS8475†					
50A 125/250V AC	CS6375					
50A 3Ø 250V AC	CS8375					
Receptacle	Black phenolic	—	50A 3Ø 480V AC	CS8175		
			50A 125V AC	CS6370		
			50A 250V AC	CS8269		
			50A 480V AC	CS8469†		
			50A 125/250V AC	CS6369		
50A 3Ø 250V AC	CS8369					
50A 3Ø 480V AC	CS8169					



Plug



Connector



Flanged Inlet



Receptacle

†Not CSA certified.



HBL® Series 50A Twist-Lock® Devices

Description	Cord Diameter	Rating			
Plugs	Nylon housing, thermoplastic polyester interior .830"-1.250" (21.08-31.75)	50A 250V DC 50A 600V AC	HBL3763C	HBL3765C	HBL7765C
Connector body	Nylon housing, thermoplastic polyester interior .830"-1.250" (21.08-31.75)	50A 250V DC 50A 600V AC	HBL3762C	HBL3764C	HBL7764C
Flanged inlet	Zinc plated steel casing, thermoset interior	50A 250V DC 50A 600V AC	HBL3777	HBL3775	HBL7958
	Zinc plated steel casing, thermoset interior with lift cover	50A 250V DC 50A 600V AC	HBL3767	HBL3768	HBL7968
Receptacle	Black phenolic	50A 250V DC 50A 600V AC	HBL3771	HBL3769	HBL7379

Female configuration shown.



Plug



Connector



Flanged Inlet with Lift Cover




Receptacle

Accessories

Accessories for FS/FD Box Mounting

Description			Catalog Number
Weatherproof receptacle lift cover plates	Corrosion resistant thermoplastic	Gray Yellow	HBL7774WO HBL77CM74WO
	Cast aluminum		HBL7770
Receptacle plates	Cast aluminum; for use with HBL® Series 50A Twist-Lock devices	with lift cover no lift cover	HBL7382* HBL7383
	Stainless steel single gang wallplate		SS750^

*Not UL Listed "WDL Closed" | *IP20 suitability

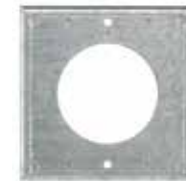

Receptacle 1/2" Raised Cover

Description	Catalog Number
Galvanized steel; fits 4" square or 2-gang box	HBL50SC^

*IP20 suitability

Conduit Adapters

Description	NPT Thread Size	Catalog Number
Thermoplastic housing for use with CS style 50A Twist-Lock® devices	1/2"	CS50CA05
	3/4"	CS50CA34
	1"	CS50CA10



Weatherproof Boots

Description		Catalog Number
Seal-Tite® triple seal black elastomeric cover	for plugs when used with cord sets and for connector bodies when used with flanged inlets	HBL7716C†
	for connector bodies when used with cord sets	HBL7717C†

†Not UL Listed



Inlet Closure Plug

Description	Catalog Number
Black closure plug	HBL4892†

†Not UL Listed



Replacement Parts

Description	Catalog Number
Cord clamp kit	HBLCSCK



50 Amp Twist-Lock® Devices



Related Products

Spider® Temporary Power Distribution Boxes

Rating	Type	Qty	Receptacle Rating	Catalog Number
50A 120/240V AC (Maximum)	Straight Blade	6	20A, 125V	TPDS
	Twist-Lock®	1	30A, 250V	
	Twist-Lock® (Inlet)	1	50A, 125/250V	
	Twist-Lock® (Outlet)	1	50A, 125/250V	
50A 120/240V AC (Maximum)	Twist-Lock®	6	20A, 125V	TPDL
	Twist-Lock®	1	30A, 250V	
	Twist-Lock® (Inlet)	1	50A, 125/250V	
	Twist-Lock® (Outlet)	1	50A, 125/250V	



Temporary Power Cables

Rating	Cable Type	Length (ft)	Catalog Number
50A 125/250V	6/3, 8/1	50	TPC50
		100	TPC100



Temporary Power Receptacle

Description	Rating	Catalog Number
Pre-wired wall mount receptacle with 3R enclosure and 2' wire leads	50A 125/250V	SR50

Hubbell Product Literature



**Circuit-Lock®
Motor
Disconnects**



**IEC Pin
and Sleeve
Devices**



**Watertight
Wiring Devices**

HUBBELL®
Wiring Device-Kellems

hubbell.com/wiringdevice-kellems/en

