



light source

- work equipment**
- connected load**
- Power consumption**
- luminous flux**
- luminous efficacy**
- colour temperature**
- color rendering index (CRI)**
- glare control**
- System of protection**
- class of protection**
- operation**
- luminaire body**
- lamp cover**
- tubular sections**
- weight (net)**
- mains lead**

- Fastening**
- special features**


- LED
- Energy efficiency category A/A+/A++
- electronic transformer
- 100-240 V; 50/60 Hz
- approx. 24 W
- approx. 1100 lm
- approx. 45 lm/W
- neutral white, approx. 4000 K
- >= 80
- conical prismatic screen
- IP20
- I
- multi-function switch
- sectional aluminium, ESD-coat of lacquer, black
- acrylic clear
- black
- approx. 1.9 kg
- approx. 3,4 m; mains plug
- CEE 7/VI
- screw-down flange, table clamp (accessory)
- ESD version



CEE 7/VI

illuminance

distance: 50 cm
Em: 1016 lx
Emax: 2671 lx
Emin: 180 lx

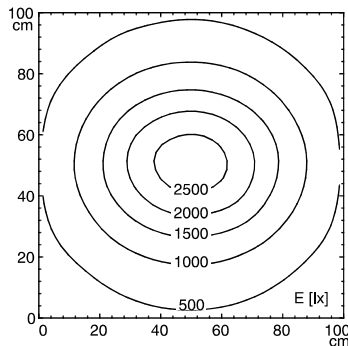

luminous intensity

