
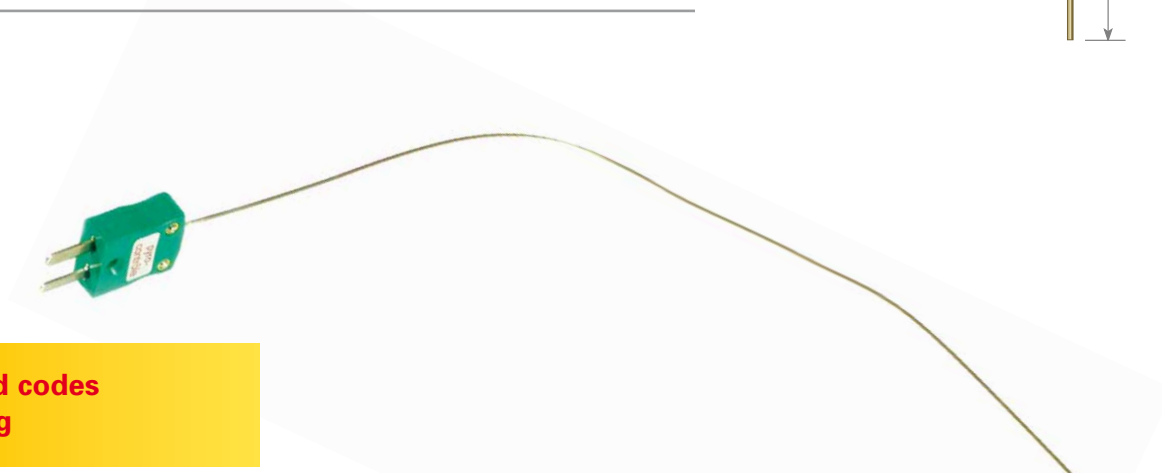



Description:

- J type thermocouple, sheathed, in compliance with NF EN 61615 standard insulated hot junction. Simple (1 TC)
- 304L protective stainless steel sheathing
available in: L1 length and Ø
- Miniature male connector
- Withstands temperatures up to 300 °C
Heat resistance decreases with diameter (see p. 6)

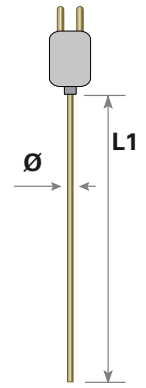

Models and codes for ordering

TC Qty	L1 (mm)	TCG11J Ø 1 mm	TCG11J Ø 1.5 mm	TCG11J Ø 2 mm
1 x TC	250	L221122-009	L221123-009	L221124-009
	500	L221122-014	L221123-014	L221124-014
	1000	L221122-024	L221123-024	L221124-024
	2000	L221122-034	L221123-034	L221124-034
	3000	L221122-038	L221123-038	L221124-038

 

**Connection accessories:
adjustable compression fitting**

- Stainless steel body and ferrule
- Pressure resistance: see p. 7

Other types of connection:
see connection components

Threading	Sheath Ø	Code
1/8" NPT	1,5 mm	L078827-000
1/8" NPT	2 mm	L078828-000



Electrical connection accessories:

Connector	Code	Extension cable	Code
J miniature female connector	L12588J-000	J thermocouple, miniature female connector/naked wire, 2 m long PVC cable	L262J12-200

Other types of electrical connection: see electrical connection