




Lineman's Pliers Bolt Thread-Holding, 9-Inch

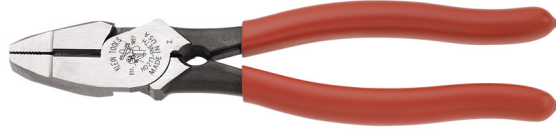

The hinge opening on these Lineman's Pliers holds and cleans 5/8-Inch (16 mm) pole line and hardware bolts or threaded rods. Thicker, dipped handles are more comfortable and easier to grab with gloved hands. They are forged, precision machined, hardened, and carefully tempered for maximum strength. Klein pliers provide exceptional performance and durability.

Specifications

Type:	Side Cutting Pliers	Application:	5/8" (15.9 mm) Pole Line and Hardware Bolts, Threaded Rods
Overall Length:	9.34" (23.7 cm)	Material:	Steel
Nose Type:	New England	Jaw Length:	1.594" (4.1 cm)
Jaw Width:	1.25" (3.2 cm)	Jaw Thickness:	0.625" (1.6 cm)
Jaw Capacity:	1.42" (3.6 cm)	Knife Length:	0.781" (2 cm)
Joint Type:	Hot Riveted	Handle Color:	Light Red
Handle Finish:	Heavy Plastic-Dipped	Handle Length:	6.875" (17.5 cm)
Insulated:	No	Tether Capable:	No
Weight:	1.2 lb (0.5 kg)		