

DYMO®

LabelManager™ 160

CREATE LABELS FAST WITH SMART KEYS

Just type your text, format it with one-touch smart keys and print!
It's easy to create professional labels in and around the office.

Features

- Large LCD Display
- Computer-style keyboard
- One-touch Smart Keys for fast formatting
- 20+ ways to form text
- 200+ symbols and clip-art images
- Print up to 1/2 in (12mm) wide labels
- Powered by 6xAAA alkaline batteries (not included) or optional adapter



Single Unit Includes:

- LabelManager 160
- D1 Starter Label Cassette, 12mm x 3m Black on White
- Quick Start Guide
- 2 + 1 - Year Limited Warranty*



Quick Specs

| | |
|-----------------------------|---------------------------------|
| Unit Dimensions (H x W x L) | 118 x 203 x 49 mm |
| Weight (excluding battery) | 350 g |
| Mac®/PC Compatible | No |
| Accepts Label Sizes | 6mm, 9mm and 12mm |
| Tape Platform | D1, Durables |
| Resolution | 180 dpi |
| Printing System | Thermal Transfer |
| Print Speed | 12 mm/sec |
| Barcodes | No |
| Cutter Type | Manual |
| Batteries | 6 AAA (not included) |
| Adapter | Yes (optional, sold separately) |
| Networking | No |
| Country of Origin | China |

| Item Number | Description | Unit | Length (cm) | Width (cm) | Height (cm) | QTY | EAN | Customer Price |
|----------------------------|-------------------------|------|-------------|------------|-------------|-----|---------------|----------------|
| S0946350 | LabelManager 160 AZERTY | Unit | 6.5 | 16.0 | 26.5 | 1 | 3501170946350 | |
| Accessories (www.dymo.com) | | | | | | | | |
| S0721440 | Charging Adapter | Unit | 11.5 | 6.0 | 9.0 | 1 | - | |

* +1 year if registered on the DYMO® website

www.DYMO.com

D1 Standard Polyester Labels

For hundreds of tasks around the office or home office, such as filing, storage and asset tracking.
Temperature rating: -18°C to 90°C

| D1 STANDARD LABELS (3 m) | 6 mm | 9 mm | 12 mm |
|------------------------------|----------|----------|----------|
| ABC | - | - | 2084349 |
| ABC | - | - | 2084401 |
| D1 STANDARD LABELS (7 m) | 6 mm | 9 mm | 12 mm |
| ABC | S0720780 | S0720680 | S0720530 |
| ABC | S0720770 | S0720670 | S0720500 |
| ABC | S0720790 | S0720730 | S0720580 |
| ABC | - | S0720710 | S0720560 |
| ABC | - | S0720740 | S0720590 |
| ABC | - | S0720720 | S0720570 |
| ABC | - | - | S0720610 |
| ABC | - | S0720690 | S0720540 |
| ABC | - | - | S0720510 |
| ABC | - | - | S0720600 |
| ABC | - | S0720700 | S0720550 |
| ABC | - | - | S0720520 |
| D1 STANDARD MULTIPACKS (7 m) | 6 mm | 9 mm | 12 mm |
| ABC | - | 2093096 | 2093097 |



D1 Durable Vinyl Labels

Industrial strength adhesive helps to ensure labels stay stuck to a variety of surfaces.
Temperature rating: -40°C to 80°C

| D1 DURABLE LABELS (3 m) | 12 mm |
|---------------------------|---------|
| ABC | 1978366 |
| ABC | 1978365 |
| ABC | 1978367 |
| D1 DURABLE LABELS (5.5 m) | 12 mm |
| ABC | 1978364 |



D1 Permanent Polyester Labels

Professional, polished finish ideal for panels, blocks, faceplates, shelves, bins and more.
Temperature rating: -40°C to 150°C*

| D1 PERMANENT POLYESTER (5.5 m) | 12 mm |
|--------------------------------|----------|
| ABC | S0718060 |


*depends on surface



D1 Flexible Nylon Labels

Specifically designed for curved surfaces and wire and cable marking.
Temperature rating: -40°C to 60°C

| D1 FLEXIBLE NYLON (3.5 m) | 12 mm |
|---------------------------|----------|
| ABC | S0718040 |

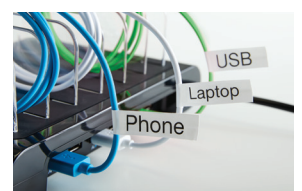

The DYMO® high quality labels are made in Belgium