



# 101-790

26 DOMESTIC CONTACTS

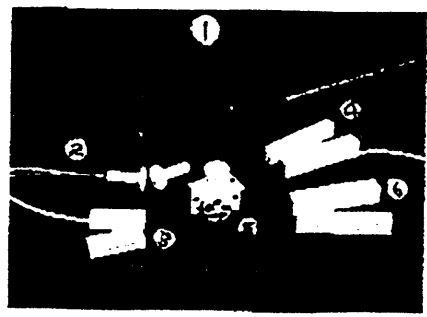


- 1. RS 001
- 2. FC 503
- 3. SC 525
- 4. SC 513
- 5. FC 504/505
- 6. SC 516/517

INDUSTRIAL CONTACTS

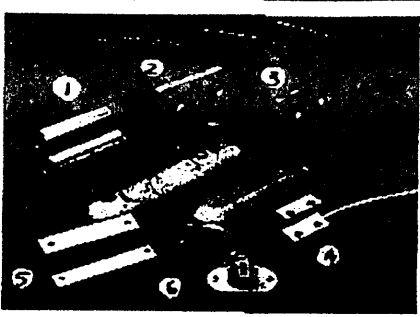

- 1. GP 002
- 2. RS 002
- 3. RS 005
- 4. SC 555
- 5. SC 550
- 6. FC 509/WH

EURO CONTACTS

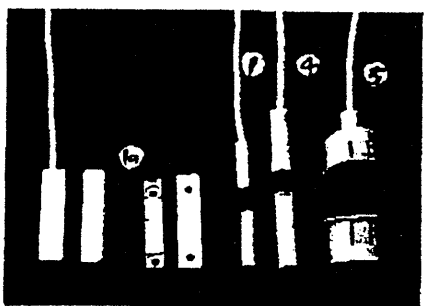

- 1. FS 610
- 1a. FS 610 c/w Surface Kit
- 4. FC 620
- 5. FC 620/SDA c/w steel door adaptor

AT A GLANCE CHECK LIST

FEATURES  
All operating gaps are specified as 'pull apart', when the magnet is directly adjacent to the switch.

DOMESTIC Model	Type	Connections	Size	Needs	Pull in Op. Gap	Material
FC 503	Flush Round Cap	4 Wire	9.5 Dia x 25mm	1	15mm	Polystyrene
FC 505	Flush Rectangular Cap	5 Term	19 Dia x 15mm	1	13mm	Polystyrene
FC 504	Flush Rectangular Cap	5 Term	19 Dia x 15mm	1	18mm	Polystyrene
SC 517	Surface	5 Term	65 x 13.5 x 13mm	1	20mm	Polystyrene
SC 516	Surface	5 Term	65 x 13.5 x 13mm	1	15mm	Polystyrene
SC 525	Plastic Push	1 Mtr. 4 Core	38 x 15 x 8mm	1	20mm	Polystyrene
SC 513	Surface	1 Mtr. 4 Core	65 x 13.5 x 13mm	1	20mm	Polystyrene
RS 001	Roller Shutter Plastic	Tubed 4 Wire	150 x 50 x 10mm	1	30mm	Polystyrene & Metal
INDUSTRIAL						
GP 001	Angle Contact	0.5mm Flexible Armoured 4 Wire	80 x 15 x 27mm	1	50mm	Aluminium
GP 002	Angle Contact	0.5mm Flexible Armoured 4 Wire	80 x 15 x 27mm	2	50mm	Aluminium
SC 550	Large Surface	6 Term Tamperproof Case	85 x 25 x 20mm	1	30mm	Polystyrene
SC 555	Push Door	1m 4 Core	40 x 14 x 10mm	1	20mm	Aluminium
FC 509 WH1	Heavy Duty 1" Quickfit	6 Term Oval Cap	25 Dia x 15mm	2	25mm	Polystyrene + Metal
FC 509 WH2	Heavy Duty 1" Quickfit	6 Term Oval Cap	25 Dia x 15mm	1	25mm	Polystyrene + Metal
RS 002	Roller Shutter Aluminium	0.5mm Flexible Armoured Cable	(Switch Body) 175 x 50 x 15mm	1	65mm	Aluminium
RS 005	Low Profile Roller Shutter	0.5mm Flexible Armoured Cable	(Switch Body) 130 x 10 x 45mm	1	50mm	Aluminium
EURO RANGE						
FS 610	Flush Surface	3 Mtr. 4 Core	6 dia x 26mm	1	15mm	Polystyrene
Complete with surface adaptor kit						
FS 620	Flush	3 Mtr. 4 Core	9.5 dia x 33mm	1	30mm	Polystyrene
FC 620/SDA	Steel door adaptor kit for FC 620					

\* SC516  
Surface 5 Term  
65 x 13.5 x 13 mm  
1 15mm  
Polystyrene

101-789  
101-790