




Socket button head screws

Dimensions

ISO 7380
BS 4168

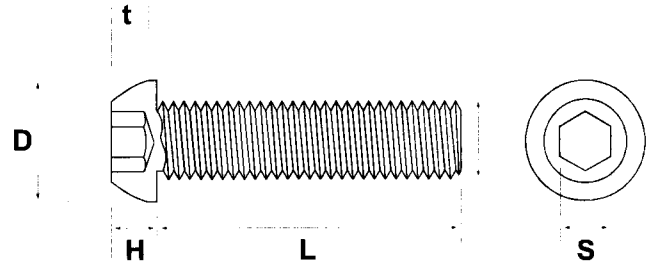

Materials / Finishes:
Steel 10.9 high tensile / Self colour
Other materials and finishes available on request

d	M3	M4	M5	M6	M8	M10	M12
Max D	5.7	7.6	9.5	10.5	14	17.5	21
Max H	1.65	2.2	2.75	3.3	4.4	5.5	6.6
S (key size)	2	2.5	3	4	5	6	8
t min	1.04	1.3	1.56	2.08	2.6	3.12	4.16

Preferred sizes - Steel

d	M3	M4	M5	M6	M8	
L	4	TR				
	5	TR				
	6	TR	TR	TR		
	8	TR	TR	TR		
	10	TR	TR	TR	TR	TR
	12	TR	TR	TR	TR	TR
	16	TR	TR	TR	TR	TR
	20		TR	TR	TR	TR
	25		TR	TR	TR	TR
	30			TR	TR	TR
	35			TR	TR	TR
	40			TR	TR	TR
	45				TR	TR
	50				TR	