

Socket countersunk screws



Dimensions

DIN 7991


ISO 10642

BS 4168

Materials / Finishes:

Steel 10.9 high tensile / Self colour

Other materials and finishes available on request

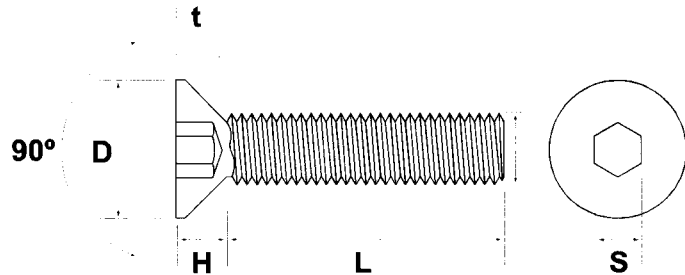

d	M3	M4	M5	M6	M8	M10	M12
Max D	6	8	10	12	16	20	24
Max H	1.7	2.3	2.8	3.3	4.4	5.5	6.5
S (key size)	2	2.5	3	4	5	6	8
t min	1.2	1.8	2.3	2.5	3.5	4.4	4.6

Preferred sizes - Steel

d	M3	M4	M5	M6	M8
L	6	TR	TR		
	8	TR	TR		
	10	TR	TR	TR	TR
	12	TR	TR	TR	TR
	16	TR	TR	TR	TR
	20	TR	TR	TR	TR
	25	TR	TR	TR	TR
	30			TR	TR
	35				TR
	40				TR
50				TR	