

斯闊企業股份有限公司
S.SQUARE ENTERPRISE COMPANY,LTD.




普崙電子股份有限公司
PRO-WAVE ELECTRONICS CORPORATION

Model Number : 800FS049

Speci fi cation:		Horizontal beam directivity	±360°
Resonance Frequency	77 KHz	Vertical beam directivity	±43°
Resonance Q	5 max	Drive voltage	150 Vp-p for Burst
Bandwidth of 6 db	15 KHz min		
Minimum Sound Pressure Output	69 dB re 20 mPa @ 10 cm, 30Vp-p	Environmental Characteristics:	
Capacitance	210±20% pF	Storage Temperature	-20°C- +60°C
PVDF Thickness	30mm	Operating Temperature	+5°C- +60°C

Di mensi on:

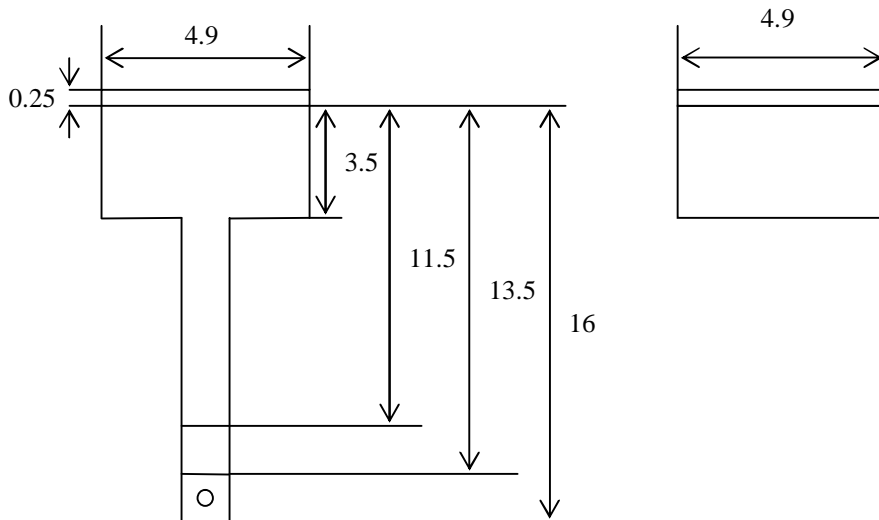

Unit: mm

Supplied by Midas Components Ltd - 01493 602602 - www.midascomponents.co.uk