

**TERMSERIES**  
**TRP 60VUC 1CO 16A**
**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

 
D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

**Product image**


Similar to illustration

TERMSERIES relay module, complete modules consisting of

a relay and a base with AC/DC/UC coils, available in different versions:

- With screw and tension-clamp connection
- Optionally with multiple-voltage input: 24...230 V UC
- With various protective circuits in the input (free-wheel diode, RC element)
- Illuminated ejection lever

**General ordering data**

|            |                                                                                                                                                              |
|------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Type       | TRP 60VUC 1CO 16A                                                                                                                                            |
| Order No.  | <a href="#">2617970000</a>                                                                                                                                   |
| Version    | TERMSERIES, Relay module, Number of contacts: 1 CO contact AgNi, Rated control voltage: 60 V UC $\pm 10\%$ , Continuous current: 16 A, PUSH IN with actuator |
| GTIN (EAN) | 4050118670868                                                                                                                                                |
| Qty.       | 10 pc(s).                                                                                                                                                    |

Creation date April 30, 2020 11:46:46 AM CEST

Catalogue status 17.04.2020 / We reserve the right to make technical changes.

**TERMSERIES**  
**TRP 60VUC 1CO 16A**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

**Technical data**
**Dimensions and weights**

|            |         |                 |            |
|------------|---------|-----------------|------------|
| Width      | 12.8 mm | Width (inches)  | 0.504 inch |
| Height     | 89.4 mm | Height (inches) | 3.52 inch  |
| Depth      | 87.8 mm | Depth (inches)  | 3.457 inch |
| Net weight | 58 g    |                 |            |

**Temperatures**

|                             |                                                                                |                             |                |
|-----------------------------|--------------------------------------------------------------------------------|-----------------------------|----------------|
| Humidity                    | 5-95% relative humidity,<br>$T_u = 40^\circ\text{C}$ , without<br>condensation | Operating temperature, max. | 60 °C          |
| Operating temperature, min. | -40 °C                                                                         | Storage temperature, max.   | 85 °C          |
| Storage temperature, min.   | -40 °C                                                                         | Operating temperature       | -40 °C...60 °C |
| Storage temperature         | -40 °C...85 °C                                                                 |                             |                |

**Rated data UL**

|                                               |                                    |                                                      |
|-----------------------------------------------|------------------------------------|------------------------------------------------------|
| Ambient temperature (operational), max. 60 °C | Connection cross-section AWG, min. | AWG 26                                               |
| Connection cross-section AWG, max.<br>AWG 14  | Type of conductor                  | rigid copper conductor,<br>flexible copper conductor |
| Pollution severity level<br>2                 | Altitude                           | ≤ 2000 m, above sea level                            |

**Input**

|                                                                                   |                                  |                                       |                                      |
|-----------------------------------------------------------------------------------|----------------------------------|---------------------------------------|--------------------------------------|
| Rated control voltage                                                             | 60 V UC ± 10 %                   | Rated current AC                      | 8 mA                                 |
| Rated current DC                                                                  | 6.1 mA                           | Power rating                          | 480 mVA / 360 mW                     |
| Pull-in/drop-out voltage, typ.                                                    | 36 V / 13 V AC<br>40 V / 14 V DC | Pull-in/drop-out current, typ.        | 5 mA / 2.5 mA AC<br>4 mA / 1.2 mA DC |
| Status indicator                                                                  | Green LED                        | Protective circuit                    | Rectifier                            |
| Coil voltage of the replacement relay<br>deviating from the rated control voltage | Yes                              | Coil voltage of the replacement relay | 60 V DC                              |

**Output**

|                                         |              |                                         |                               |
|-----------------------------------------|--------------|-----------------------------------------|-------------------------------|
| Rated switching voltage                 | 250 V AC     | Max. switching voltage, AC              | 250 V                         |
| Max. switching voltage, DC              | 250 V        | Continuous current                      | 16 A                          |
| Inrush current                          | 30 A / 4 s   | AC switching capacity (resistive), max. | 4000 VA                       |
| DC switching capacity (resistive), max. | 384 W @ 24 V | Switch-on delay                         | ≤ 11 ms                       |
| Switch-off delay                        | ≤ 7 ms       | Min. switching power                    | 10 mA @ 10 V, 100 mA @<br>5 V |
| Max. switching frequency at rated load  | 0.1 Hz       |                                         |                               |

**Contact data**

|              |                     |                         |                                       |
|--------------|---------------------|-------------------------|---------------------------------------|
| Contact type | 1 CO contact (AgNi) | Mechanical service life | 30 x 10 <sup>6</sup> switching cycles |
|--------------|---------------------|-------------------------|---------------------------------------|

**General data**

|                                      |       |             |       |
|--------------------------------------|-------|-------------|-------|
| Rail                                 | TS 35 | Test button | No    |
| Mechanical switch position indicator | No    | Colour      | black |
| UL 94 flammability rating            | V-0   |             |       |

**TERMSERIES**  
**TRP 60VUC 1CO 16A****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

**Technical data****Insulation coordination**

|                                     |                             |                                                |                              |
|-------------------------------------|-----------------------------|------------------------------------------------|------------------------------|
| Rated voltage                       | 300 V                       | Surge voltage category                         | III                          |
| Pollution severity                  | 2                           | Protection degree                              | IP20                         |
| Dielectric strength, Input/Output   | 1.2 kV <sub>eff</sub> / 5 s | Creepage and clearance distance input – output | ≥ 5.5 mm                     |
| Dielectric strength of open contact | 1 kV <sub>eff</sub> / 1 min | Dielectric strength to mounting rail           | 4 kV <sub>eff</sub> / 1 Min. |
| Impulse withstand voltage           | 6 kV (1.2/50 µs)            |                                                |                              |

**Further details of approvals / standards**

|                         |                                        |                         |            |
|-------------------------|----------------------------------------|-------------------------|------------|
| Standards               | EN 50178, EN 55011, EN 61000-6-1, 2, 4 | Certificate No. (DNVGL) | TAA00001E5 |
| Certificate no. (cULus) | E141197                                |                         |            |

**Connection data**

|                                                                                         |                       |                                                                                         |                      |
|-----------------------------------------------------------------------------------------|-----------------------|-----------------------------------------------------------------------------------------|----------------------|
| Wire connection method                                                                  | PUSH IN with actuator | Stripping length, rated connection                                                      | 8 mm                 |
| Clamping range, rated connection                                                        | 1.5 mm <sup>2</sup>   | Clamping range, min.                                                                    | 0.14 mm <sup>2</sup> |
| Clamping range, max.                                                                    | 2.5 mm <sup>2</sup>   | Wire connection cross section AWG, min.                                                 | AWG 26               |
| Wire connection cross section AWG, max.                                                 | AWG 14                | Wire cross-section, solid, min.                                                         | 0.14 mm <sup>2</sup> |
| Wire cross-section, solid, max.                                                         | 2.5 mm <sup>2</sup>   | Wire connection cross-section, finely stranded, min.                                    | 0.14 mm <sup>2</sup> |
| Wire connection cross section, finely stranded, max.                                    | 2.5 mm <sup>2</sup>   | Wire cross-section, finely stranded, min. (AWG)                                         | AWG 26               |
| Wire cross-section, finely stranded, max. (AWG)                                         | AWG 14                | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, min. | 0.15 mm <sup>2</sup> |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, max. | 1.5 mm <sup>2</sup>   | Conductor cross-section, flexible, AEH (DIN 46228-1), min.                              | 0.15 mm <sup>2</sup> |
| Conductor cross-section, flexible, AEH (DIN 46228-1), max.                              | 1.5 mm <sup>2</sup>   | Twin wire-end ferrules, min.                                                            | 0.5 mm <sup>2</sup>  |
| Twin wire-end ferrules, max.                                                            | 1 mm <sup>2</sup>     | Blade size                                                                              | 0.4 x 2.0 mm         |

**Classifications**

|             |             |            |             |
|-------------|-------------|------------|-------------|
| ETIM 6.0    | EC001437    | ETIM 7.0   | EC001437    |
| eClass 9.0  | 27-37-16-01 | eClass 9.1 | 27-37-16-01 |
| eClass 10.0 | 27-37-16-01 |            |             |

**Approvals**

Approvals

**Downloads**

|                                             |                                                                         |
|---------------------------------------------|-------------------------------------------------------------------------|
| Approval/Certificate/Document of Conformity | <a href="#">EU Konformitätserklärung / EU Declaration of Conformity</a> |
| Engineering Data                            | <a href="#">STEP</a>                                                    |
| User Documentation                          | <a href="#">Beipackzettel / Package Insert – multilingual</a>           |

Creation date April 30, 2020 11:46:46 AM CEST


Catalogue status 17.04.2020 / We reserve the right to make technical changes.

## TERMSERIES TRP 60VUC 1CO 16A


**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

## Drawings


### Wiring diagram

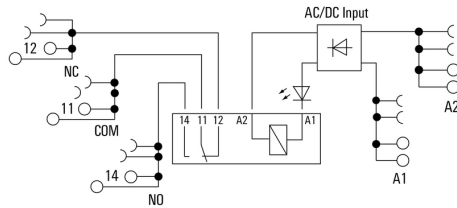

### Graph

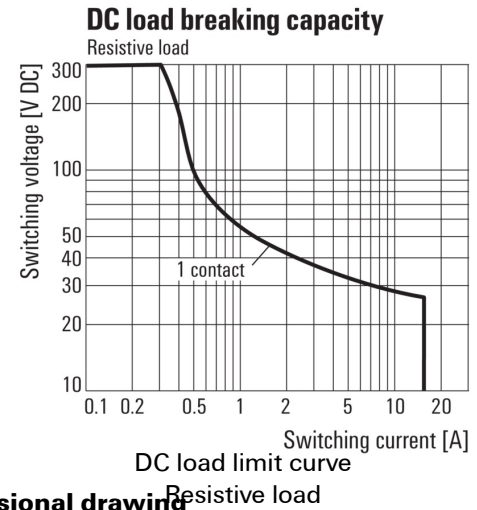


### Graph

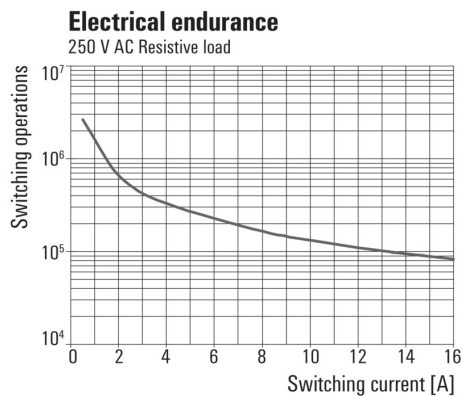

Electrical service life 230 V AC resistive load  
230 V AC resistive load

### Dimensional drawing

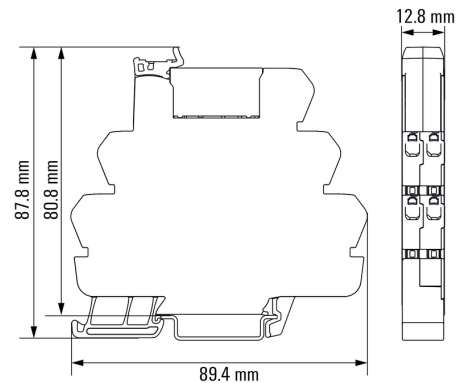

## TERMSERIES TRP 60VUC 1CO 16A

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
www.weidmueller.com

## Accessories

### Supply module



TERMSERIES accessories include:

- Spare relay
- Base
- Partition plates
- Cross-connections
- Power-feed modules

### General ordering data

|            |                            |                                                              |
|------------|----------------------------|--------------------------------------------------------------|
| Type       | TXZ SUPPLY                 | Version                                                      |
| Order No.  | <a href="#">1240790000</a> | TERMSERIES, Supply module, Number of contacts: 5, Continuous |
| GTIN (EAN) | 4050118028164              | current: 10 A, Tension-clamp connection                      |
| Qty.       | 10 pc(s).                  |                                                              |
| Type       | TXS SUPPLY                 | Version                                                      |
| Order No.  | <a href="#">1240780000</a> | TERMSERIES, Supply module, Number of contacts: 5, Continuous |
| GTIN (EAN) | 4050118028140              | current: 10 A, Screw connection                              |
| Qty.       | 10 pc(s).                  |                                                              |
| Type       | TXP SUPPLY                 | Version                                                      |
| Order No.  | <a href="#">2618940000</a> | TERMSERIES, Supply module, Number of contacts: 5, Continuous |
| GTIN (EAN) | 4050118667592              | current: 10 A, PUSH IN with actuator                         |
| Qty.       | 10 pc(s).                  |                                                              |

### Blank



WS markers are the perfect match for the W-series connectors. Thanks to their system compatibility, the WS tags can also be used with the I-series and the Z-series. The large marking surfaces do not only permit long character strings but also multi-line text. WS markers are ideal for labels with long, customised character strings. Thanks to the proven MultiCard format, printing with laser printer, PrintJet ADVANCED, plotter or MC-Mobilo is possible.

- Can be fitted in strips or individually
- Markers in proven MultiCard format

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

### General ordering data

|            |                            |                                                         |
|------------|----------------------------|---------------------------------------------------------|
| Type       | WS 10/12 MC NE WS          | Version                                                 |
| Order No.  | <a href="#">1905970000</a> | WS, Terminal marker, 10 x 12 mm, Pitch in mm (P): 12.00 |
| GTIN (EAN) | 4032248528127              | Weidmueller, white                                      |
| Qty.       | 300 pc(s).                 |                                                         |

## TERMSERIES TRP 60VUC 1CO 16A

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

## Accessories

### Slotted screwdriver

Slotted screwdriver with rounded blade SD DIN 5265, ISO 2380/2, output to DIN 5264, ISO 2380/1. ChromTop tip, SoftFinish grip



### General ordering data

|            |                            |                                                                                      |
|------------|----------------------------|--------------------------------------------------------------------------------------|
| Type       | SDS 0.4X2.0X60             | Version                                                                              |
| Order No.  | <a href="#">9037160000</a> | Screwdriver, Blade width (B): 2 mm, Blade length: 60 mm, Blade thickness (A): 0.4 mm |
| GTIN (EAN) | 4032248171613              |                                                                                      |
| Qty.       | 1 pc(s).                   |                                                                                      |

### Blank



WS markers are the perfect match for the W-series connectors. Thanks to their system compatibility, the WS tags can also be used with the I-series and the Z-series. The large marking surfaces do not only permit long character strings but also multi-line text. WS markers are ideal for labels with long, customised character strings. Thanks to the proven MultiCard format, printing with laser printer, PrintJet ADVANCED, plotter or MC-Mobilo is possible.

- Can be fitted in strips or individually
- Markers in proven MultiCard format

**For custom printing:** Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

### General ordering data

|            |                            |                                                                    |
|------------|----------------------------|--------------------------------------------------------------------|
| Type       | WS 10/6 M MC NE WS         | Version                                                            |
| Order No.  | <a href="#">1818400000</a> | WS, Terminal marker, 10 x 6 mm, Pitch in mm (P): 6.00 Weidmueller, |
| GTIN (EAN) | 4032248310876              | Allen-Bradley, white                                               |
| Qty.       | 600 pc(s).                 |                                                                    |

## TERMSERIES TRP 60VUC 1CO 16A

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

## Accessories

### Cross-connector



TERMSERIES accessories include:

- Spare relay
- Base
- Partition plates
- Cross-connections
- Power-feed modules

### General ordering data

|            |                            |                             |
|------------|----------------------------|-----------------------------|
| Type       | TCC 12.8/26 BL             | Version                     |
| Order No.  | <a href="#">2556460000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118566970              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | TCC 6.4/2 BK               | Version                     |
| Order No.  | <a href="#">2556470000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118566987              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | TCC 6.4/10 BK              | Version                     |
| Order No.  | <a href="#">2556480000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118566994              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | TCC 6.4/51 RD              | Version                     |
| Order No.  | <a href="#">2556410000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118566925              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | TCC 6.4/10 BL              | Version                     |
| Order No.  | <a href="#">2556440000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118566956              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | ZQV 1.5N/R6.4/19 RT        | Version                     |
| Order No.  | <a href="#">1391610000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118191783              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | TCC 6.4/2 BL               | Version                     |
| Order No.  | <a href="#">2556430000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118566949              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | TCC 6.4/10 OR              | Version                     |
| Order No.  | <a href="#">2556360000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118566673              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | TCC 12.8/26 RD             | Version                     |
| Order No.  | <a href="#">2556420000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118566932              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | TCC 12.8/26 OR             | Version                     |
| Order No.  | <a href="#">2556380000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118566697              |                             |
| Qty.       | 10 pc(s).                  |                             |

## TERMSERIES

### TRP 60VUC 1CO 16A

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

## Accessories

|            |                            |                             |
|------------|----------------------------|-----------------------------|
| Type       | TCC 6.4/2 OR               | Version                     |
| Order No.  | <a href="#">2556350000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118566826              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | ZQV 1.5N/R6.4/19 GE        | Version                     |
| Order No.  | <a href="#">1193690000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4032248976645              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | TCC 6.4/51 BL              | Version                     |
| Order No.  | <a href="#">2556450000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118566963              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | ZQV 1.5N/R6.4/2 RT         | Version                     |
| Order No.  | <a href="#">1446090000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118250886              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | TCC 6.4/51 OR              | Version                     |
| Order No.  | <a href="#">2556370000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118566680              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | ZQV 1.5N/R6.4/10 GE        | Version                     |
| Order No.  | <a href="#">1193680000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4032248976454              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | TCC 6.4/2 RD               | Version                     |
| Order No.  | <a href="#">2556390000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118566901              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | ZQV 1.5N/R6.4/2 SW         | Version                     |
| Order No.  | <a href="#">1446040000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118251067              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | TCC 6.4/10 RD              | Version                     |
| Order No.  | <a href="#">2556400000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118566918              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | ZQV 1.5N/R6.4/2 GE         | Version                     |
| Order No.  | <a href="#">1193670000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4032248976638              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | ZQV 1.5N/R6.4/2 BL         | Version                     |
| Order No.  | <a href="#">1446140000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118251074              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | TCC 12.8/26 BK             | Version                     |
| Order No.  | <a href="#">2556500000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118567014              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | ZQV 1.5N/R6.4/10 SW        | Version                     |
| Order No.  | <a href="#">1391630000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118191776              |                             |
| Qty.       | 10 pc(s).                  |                             |

Creation date April 30, 2020 11:46:46 AM CEST

## TERMSERIES TRP 60VUC 1CO 16A

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany  
 Fon: +49 5231 14-0  
 Fax: +49 5231 14-292083  
 www.weidmueller.com

## Accessories

|            |                            |                             |
|------------|----------------------------|-----------------------------|
| Type       | TCC 6.4/51 BK              | Version                     |
| Order No.  | <a href="#">2556490000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118567007              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | ZQV 1.5N/R6.4/19 BL        | Version                     |
| Order No.  | <a href="#">1391620000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118191813              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | ZQV 1.5N/R6.4/10 BL        | Version                     |
| Order No.  | <a href="#">1390350000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118190793              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | ZQV 1.5N/R6.4/10 RT        | Version                     |
| Order No.  | <a href="#">1391640000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118191660              |                             |
| Qty.       | 10 pc(s).                  |                             |
| Type       | ZQV 1.5N/R6.4/19 SW        | Version                     |
| Order No.  | <a href="#">1391600000</a> | TERMSERIES, Cross-connector |
| GTIN (EAN) | 4050118191806              |                             |
| Qty.       | 10 pc(s).                  |                             |

## Slotted screwdriver

VDE insulated slot-head screwdriver, SDI DIN 7437, ISO 2380/2, drive output acc. to DIN 5264, ISO 2380/1. SoftFinish grip



## General ordering data

|            |                            |                                                                                      |
|------------|----------------------------|--------------------------------------------------------------------------------------|
| Type       | SDIS 0.4X2.0X60            | Version                                                                              |
| Order No.  | <a href="#">9205690000</a> | Screwdriver, Blade width (B): 2 mm, Blade length: 60 mm, Blade thickness (A): 0.4 mm |
| GTIN (EAN) | 4032248772995              |                                                                                      |
| Qty.       | 1 pc(s).                   |                                                                                      |

## TERMSERIES TRP 60VUC 1CO 16A

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany  
Fon: +49 5231 14-0  
Fax: +49 5231 14-292083  
[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

### Partition plate



TERMSERIES accessories include:

- Spare relay
- Base
- Partition plates
- Cross-connections
- Power-feed modules

### General ordering data

|            |                            |                              |
|------------|----------------------------|------------------------------|
| Type       | TW TXS/TXZ R3.2            | Version                      |
| Order No.  | <a href="#">1240800000</a> | TERMSERIES, Seperation plate |
| GTIN (EAN) | 4050118028188              |                              |
| Qty.       | 10 pc(s).                  |                              |

