

A very reliable plug, rated at 10 Amps, with a screw connection for the lead wire and a screw-on rigid acetal moulding. Accepts up to 7,1mm diameter cable with a conductor of 3,5mm diameter.


MATERIALS
HOUSING : Acetal C 27021 R
TRIPLE : Brass,
CONTACTS flash gold plated
CABLE or nickel plated

LEAD ENTRY : Ø 7,1mm
WIRE : Ø 3,5mm

RATING : 10 AMPS

Dimensions

MAXIMUM CONDUCTOR SIZE 3.5mm

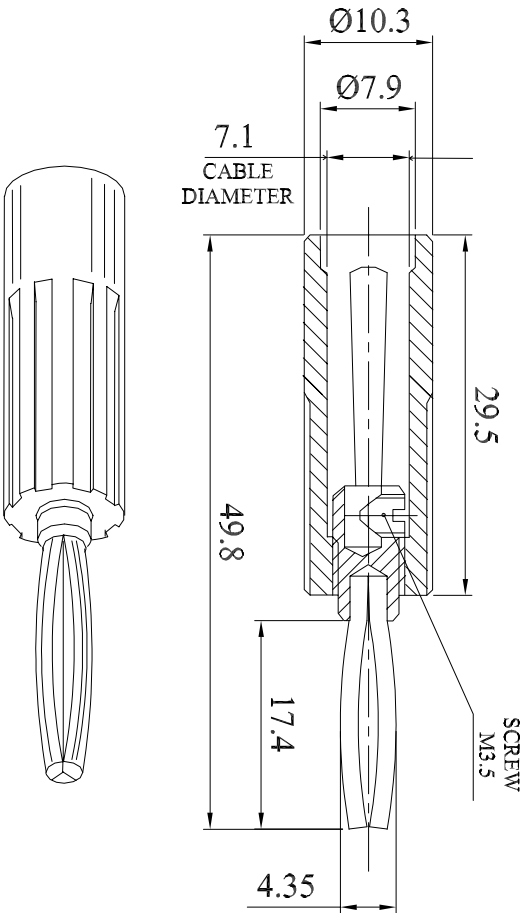

COLOUR	NICKEL	FLASH GOLD PLATING
BLACK	557-0100	557-0100-41
BLUE	557-0200	557-0200-41
BROWN	557-0300	557-0300-41
GREEN	557-0400	557-0400-41
RED	557-0500	557-0500-41
WHITE	557-0600	557-0600-41
YELLOW	557-0700	557-0700-41

CONVERTED FROM PS0130 ISS3 (11.12.95) IN JAN 2003

DrgnNo 557 SERIES			TITLE 4mm TRIPLE CONTACT PLUG			ALL DIMENSIONS IN MM ANGLES IN DECIMAL DEGREES		