
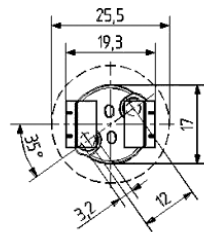


25.105.3101

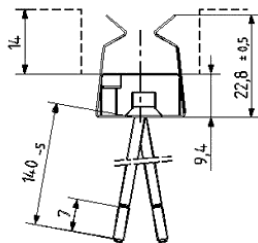

T250

10 A

50 V

◀ 1/1 ▶

◀ 1/1 ▶

Part No.	Color	Package qty.	Wt.
25.105.3101.00	other	500	8

Screw mount 12 mm centers

T-Marking: 250

Connection: Cable PTFE, rear cable entry

Housing: Housing ceramic

- Rating: 10 A / 50 V

- Housing: ceramic

- T 250 for the contacts (material Ni)

- Wires: Cu, nickel plated, 1.0 mm<sup>2</sup>,

insulation: PTFE (max. 250° C), with ferrule

free cable length: 140 mm

rear cable entry

- The method of wiring must be such that no stress or bending motions will be transferred to the contacts, thus reducing the contact / pressure on the lamp pins.