

 

16

XNES/J 210

Power supply connectors



Power supply plug, long, straight version, with solder eyes and bend protection

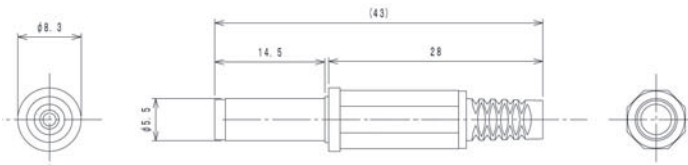

#### Environmental conditions

Temperature range -20 °C/+70 °C

#### Materials

Insulating body	PC
Contact	CuZn, nickel-plated
Insulation	ABS/PVC
Housing	PP

#### Mechanical data

Outer diameter	5,5 mm
Inner diameter	2,1 mm

#### Connectable conductors for solder area

Cable diameter 4 mm

#### Electrical data (at T<sub>amb</sub> 20 °C)

Rated current	0,5 A
Rated voltage	12 V DC
Rated impulse voltage	500 V/60 s
Insulation resistance	≥ 100 MΩ

#### Associated products

Counterparts		
☞ 1610 02	☞ 1613 14	☞ 1613 18
☞ 1614 09	☞ 1614 14	☞ 1614 16
☞ 1614 19	☞ NEB 21 R	☞ NEB/J 21
☞ NEB/J 21 C	☞ NEB/J 21 R	☞ NEK/J 210

16

XNES/J 210

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)
XNES/J 210	2	100	500

**Packaging:**

in bulk, in a cardboard box or a plastic bag