

16


NEB/J 25

Power supply connectors



Power supply chassis socket, straight version, with fixing flange, break contact and solder eyes

State: Active

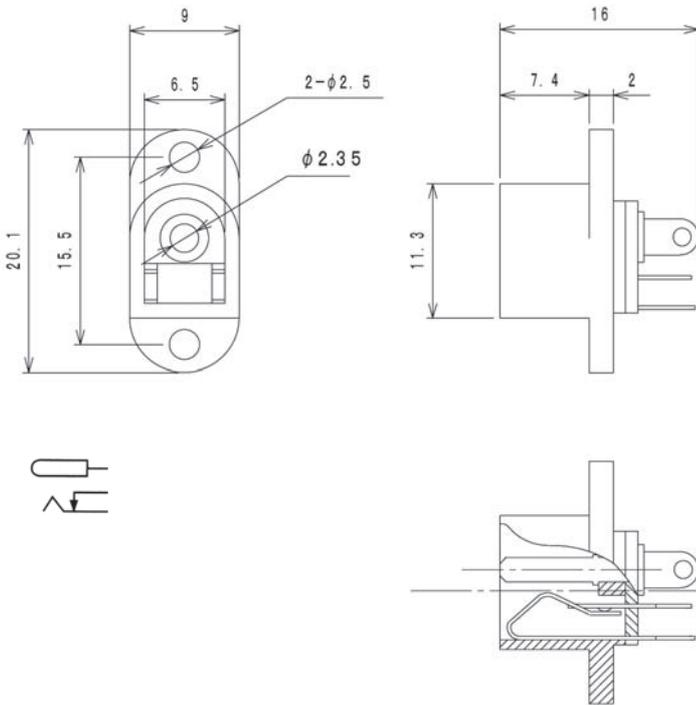

Environmental conditions

Temperature range -25 °C/+70 °C

Materials

Insulating body	PF
Contact	Cu alloy, nickel-plated/silver-plated
Housing	POM, HB according to UL94

Mechanical data

Diameter opening	6,3 mm
Diameter center pin	2,35 mm
Mating cycles	≥ 5000
Insertion force	4–20 N ¹
Withdrawal force	3–15 N ¹

¹ measured with a gauge plug

Electrical data (at T_{amb} 20 °C)

Contact resistance	≤ 30 mΩ
Rated current	1 A
Rated voltage	12 V DC
Rated impulse voltage	500 V/60 s
Insulation resistance	≥ 100 MΩ

Associated products

Counterparts			
☞ 1614 20	☞ 1633 04	☞ 1634 02	
☞ NES/J 25	☞ NES/J 250	☞ XNES/J 250	

16

NEB/J 25

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)
NEB/J 25	2	250	750

Packaging:

in bulk, in a cardboard box or a plastic bag