

03

038899


Circular connectors with threaded joint M16 acc. to IEC 61076-2-106, IP40/IP67/IP68



Protecting cap, IP68, for plugs, without chain

03

038899

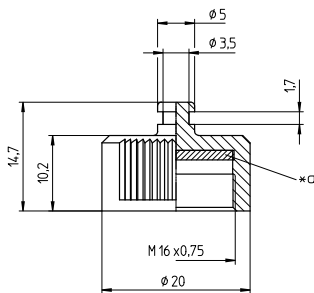

\*a flat gasket

#### Environmental conditions

Temperature range -40 °C/+85 °C

#### Materials

Cap	PC
Seal	CR

#### Mechanical data

Tightening torque connector	1-3 Nm
Tightening torque nut	1-3 Nm
Protection class	IP68 <sup>1</sup>

<sup>1</sup> according to IEC DIN EN 60529, only in locked condition with an appropriate counterpart; IPX8 requirements under agreement between manufacturer and user

#### Associated products

##### Accessories

☞ 0314	☞ 0314-1	☞ 0314-2
☞ 0315	☞ 0315-1	☞ 0315-1 U
☞ 0315-2	☞ 0316	☞ 0316-1
☞ 0316-2	☞ 0317	☞ 0317-1
☞ 0317-2	☞ 031798-1	☞ 031798-2
☞ 031799-2	☞ 0318	☞ 0318-1
☞ 0318-2	☞ 0331	☞ 0332
☞ 0332-1	☞ 033200	☞ 0365
☞ 036500	☞ SFV	☞ SGR
☞ SGV	☞ SV	☞ SV ...-8
☞ WSV		

03

038899

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)
038899	-	50	500

**Packaging:**

in a cardboard box