

03 038399


Circular connectors with threaded joint M16 acc. to IEC 61076-2-106, IP40/IP67/IP68



Protecting cap, IP68, for plugs, without chain

03

038399

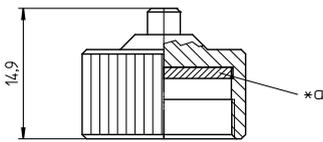

*a flat gasket

Environmental conditions

Temperature range -40 °C/+85 °C

Materials

Cap	CuZn, nickel-plated
Seal	CR
Chain	CuZn, pre-nickel and verchromt

Mechanical data

Tightening torque connector	1-3 Nm
Tightening torque nut	1-3 Nm
Protection class	IP68 ¹

¹ according to IEC DIN EN 60529, only in locked condition with an appropriate counterpart; IPX8 requirements under agreement between manufacturer and user

Associated products

Accessories

0314	0314-1	0314-2
0315	0315-1	0315-1 U
0315-2	0316	0316-1
0316-2	0317	0317-1
0317-2	031798-1	031798-2
031799-2	0318	0318-1
0318-2	0331	0332
0332-1	033200	0365
036500	SFV	SGR
SGV	SV	SV ...-8
WSV		

03

038399

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)
038399	-	50	100

Packaging:

in a cardboard box