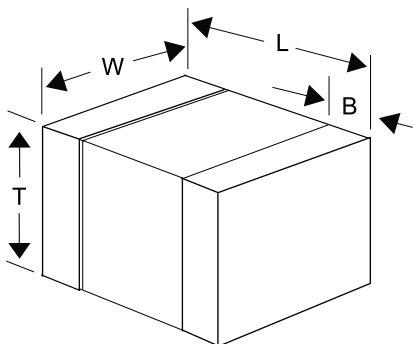


## KEMET, Z-SMS, Ferrite Beads, Noise Suppression, 750 mOhms

**Dimensions**

Chip Size	0603
L	1.6mm +/-0.15mm
W	0.8mm +/-0.15mm
T	0.8mm +/-0.15mm
B	0.3mm +/-0.2mm

**Packaging Specifications**

Packaging:	T&R
Packaging Quantity:	4000

**General Information**

Series:	Z-SMS
Style:	SMD Chip
Description:	Chip Bead Signal Line
Features:	Intended For Noise Suppression Around 200MHz, Effectively Increase Attenuation
RoHS:	Yes
Notes:	Internal Silver Printed Layer Creates A Closed Circuit Which Acts As A Magnetic Shield To Minimize Heat Generation And Crosstalk

**Specifications**

Impedance:	1500 Ohms (100 mHz)
Impedance Tolerance:	25%
Ripple Current:	250 mA (MAX)
Temperature Range:	-55/+125°C
Resistance:	0.75 Ohms