



Classic filament LEDbulbs

CLA LEDBulb ND 7-60W E27 WW ST64 CL

Featuring a classic heritage design, Classic filament LEDbulbs combine the familiar shapes of classic incandescent bulbs with the benefits of the long lasting LED technology. They deliver beautiful, decorative warm-white light while saving around 90% on energy costs compared with traditional light bulbs.

Product data


General Information		Temperature	
Cap-Base	E27 [E27]	Lamp Current (Nom)	60 mA
EU RoHS compliant	Yes	Wattage Equivalent	60 W
Nominal Lifetime (Nom)	15000 h	Starting Time (Nom)	0.5 s
Switching Cycle	20000X	Warm Up Time to 60% Light (Nom)	0.5 s
Technical Type	7-60W	Power Factor (Nom)	0.5
Light Technical		Voltage (Nom)	220-240 V
Color Code	827 [CCT of 2700K]	Controls and Dimming	
Luminous Flux (Nom)	806 lm	Dimmable	No
Color Designation	Warm White (WW)	Mechanical and Housing	
Correlated Color Temperature (Nom)	2700 K	Bulb Finish	Clear
Luminous Efficacy (rated) (Nom)	115.00 lm/W	Approval and Application	
Color Consistency	<6	Energy Efficiency Label (EEL)	A++
Color Rendering Index (Nom)	80	Energy Consumption kWh/1000 h	7 kWh
LLMF At End Of Nominal Lifetime (Nom)	70 %		
Operating and Electrical			
Input Frequency	50 to 60 Hz		
Power (Nom)	7 W		

Classic filament LEDbulbs

Product Data	
Full product code	871869674275400
Order product name	CLA LEDBulb ND 7-60W E27 WW ST64 CL
EAN/UPC - Product	8718696742754
Order code	929001387602
Numerator - Quantity Per Pack	1

Numerator - Packs per outer box	10
Material Nr. (12NC)	929001387602
Net Weight (Piece)	0.048 kg



Dimensional drawing

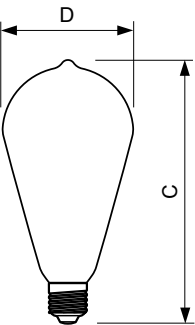

Bulb ST64 230V 7-60W 806lm 2700K E27 ND


Product	D	C
CLA LEDBulb ND 7-60W E27 WW ST64 CL	64 mm	140 mm

Photometric data

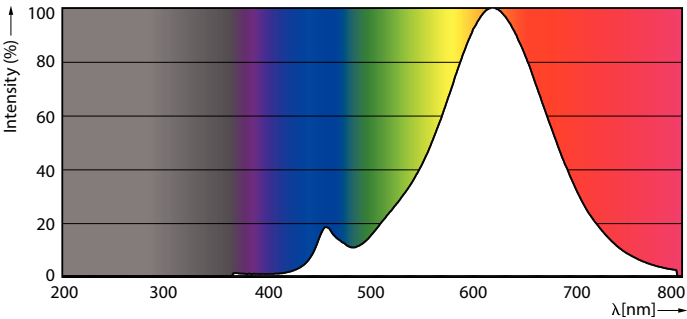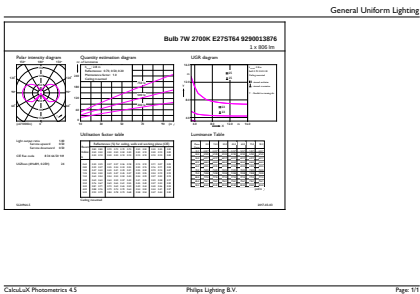

LEDbulb 60W E27 827 CL ST64 ND


LEDbulb 60W E27 827 CL A60 ND

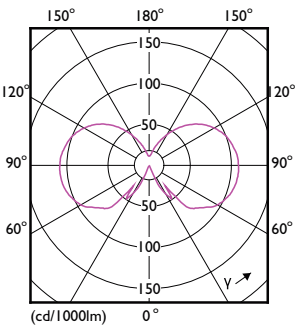


LEDbulb 60W E27 827 CL A60 ND

Classic filament LEDbulbs

Lifetime

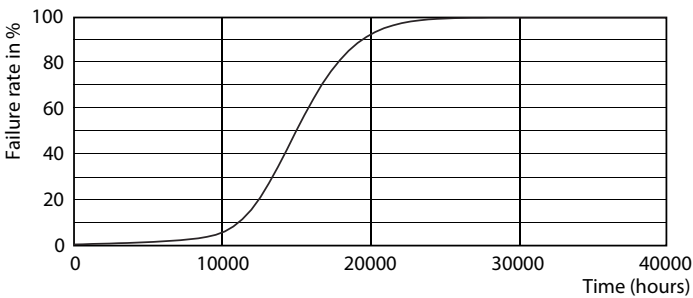

LEDbulb 60W E27 827 CL A60 ND

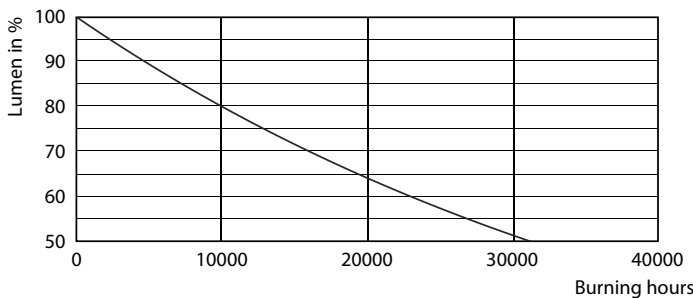

LEDbulb 60W E27 827 CL A60 ND

