



CorePro LEDspot MV

Corepro LEDspot 3.5-35W GU10 840 36D

CorePro LEDspots are a perfect fit for spot lighting and deliver warm halogen-like light. They are compatible with most existing fixtures with a GU10 or E27 base and are designed as a retrofit replacement for halogen or incandescent spots. CorePro LEDspots deliver significant energy savings and minimize maintenance cost.

Product data

General Information	
Cap-Base	GU10 [GU10]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	50000X
Technical Type	3.5-35W
Light Technical	
Color Code	840 [CCT of 4000K]
Beam Angle (Nom)	36°
Luminous Flux (Nom)	275 lm
Luminous Intensity (Nom)	590 cd
Color Designation	Cool White (CW)
Correlated Color Temperature (Nom)	4000 K
Luminous Efficacy (rated) (Nom)	78.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Luminous Flux in 90° Cone (Rated)	275 lm
Operating and Electrical	
Input Frequency	50 to 60 Hz
Power (Nom)	3.5 W


Lamp Current (Nom)	32 mA
Wattage Equivalent	35 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.5
Voltage (Nom)	220-240 V
Temperature	
T-Case Maximum (Nom)	65 °C
Controls and Dimming	
Dimmable	No
Approval and Application	
Energy Efficiency Label (EEL)	A++
Suitable For Accent Lighting	Yes
Energy Consumption kWh/1000 h	4 kWh
Product Data	
Full product code	871869672835200
Order product name	Corepro LEDspot 3.5-35W GU10 840 36D
EAN/UPC - Product	8718696728352
Order code	929001218002

CorePro LEDspot MV

Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001218002

Net Weight (Piece)	0.038 kg
--------------------	----------


Dimensional drawing

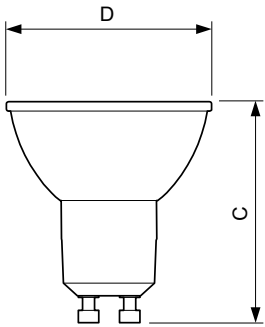


GU10 230V 4W-35W 260lm 60D 4000K GU10 ND

Product	D	C
Corepro LEDspot 3.5-35W GU10 840 36D	50 mm	54 mm

Photometric data

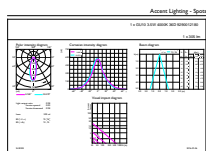


Standard Photometric ET Photo Lighting ET Page 10

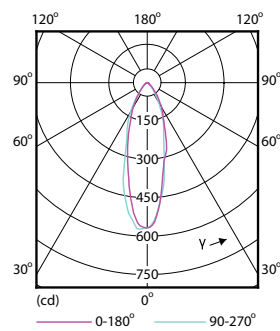

CorePro LEDspotMV 35W GU10 840 36D CLA


CorePro LEDspotMV 35W GU10 830 36D CLA

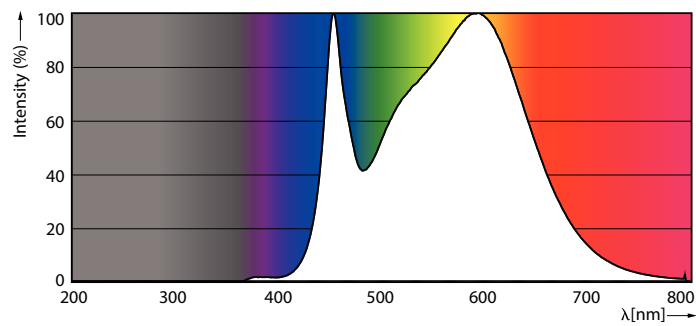

CorePro LEDspotMV 25W GU10 840 36D

CorePro LEDspot MV

Lifetime

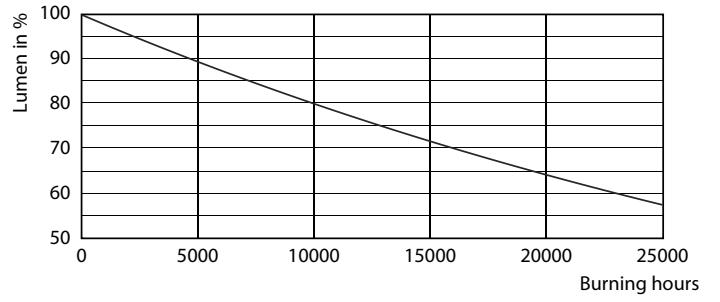

CLA LEDspotMV 50W GU10 827 36D ND

CLA LEDspotMV 50W GU10 827 36D ND

