



CorePro LEDbulb

CorePro LEDbulb D 10.5-75W A60 B22 927

LEDbulbs are compatible with existing fixtures with an E27 holder and are designed for retrofit replacement of incandescent bulbs.

Product data

General Information	
Cap base	B22 [B22]
EU RoHS compliant	Yes
Nominal lifetime (nom.)	15000 h
Switching cycle	50,000X
Technical type	10.5-75W

Light Technical	
Colour code	927
Beam Angle (Nom)	150 °
Luminous flux (nom.)	1055 lm
Colour designation	Warm white (WW)
Correlated Colour Temperature (Nom)	2700 K
Luminous efficacy (rated) (nom.)	100.00 lm/W
Colour consistency	<6
Color rendering index (nom.)	90
LLMF at end of nominal lifetime (nom.)	70 %

Operating and Electrical	
Input frequency	50 to 60 Hz
Power (Rated) (Nom)	10.5 W
Lamp current (nom.)	55 mA
Wattage equivalent	75 W
Starting time (nom.)	0.5 s
Warm-up time to 60% light (nom.)	0.5 s

Power factor (nom.)	0.9
Voltage (Nom)	220-240 V

Temperature	
T-Case maximum (nom.)	90 °C

Controls and Dimming	
Dimmable	Yes


Mechanical and Housing	
Bulb finish	Frosted

Approval and Application	
Energy efficiency label (EEL)	A+
Energy Consumption kWh/1000 h	11 kWh

Product Data	
Full product code	871869966074100
Order product name	CorePro LEDbulb D 10.5-75W A60 B22 927
EAN/UPC – product	8718699660741
Order code	66074100
Numerator – quantity per pack	1
Numerator – packs per outer box	10
Material no. (12NC)	929002069402
Net weight (piece)	0.060 kg

CorePro LEDbulb


Dimensional drawing

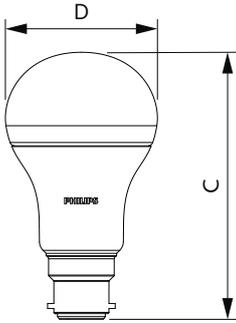


Bulb A60M 230V 11-75W 1055lm 2700K B22

Product	D	C
CorePro LEDbulb D 10.5-75W A60 B22 927	60 mm	110 mm


Photometric data

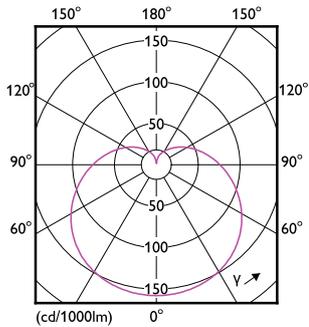

LEDBulb CorePro E27 A60 10,5W

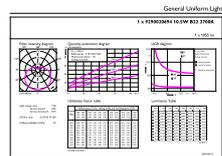



LEDBulb CorePro B22 A60 10,5W

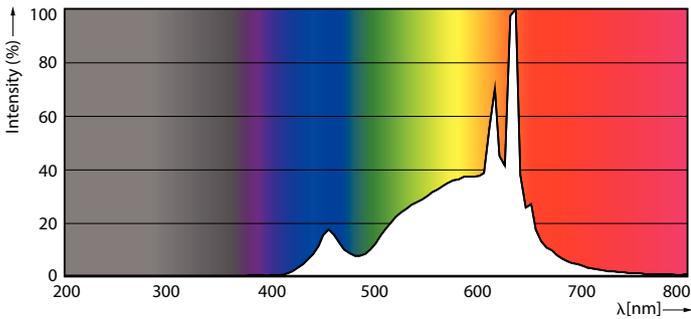

LEDBulb CorePro E27 A60 10,5W

CorePro LEDbulb

Lifetime

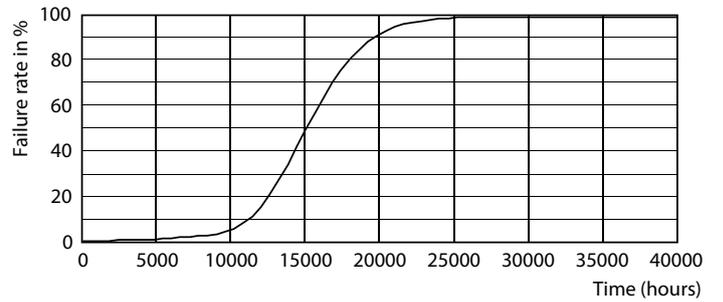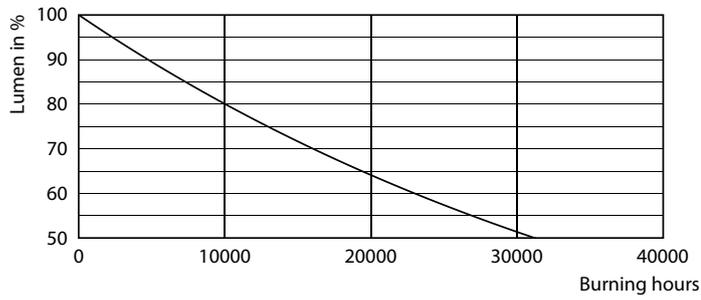

LEDBulb CorePro E27 A60

LEDBulb CorePro E27 A60

