



CorePro LED candles and lusters

Corepro Candle ND 4-25W E14 827 B35 CL

The CorePro LEDcandles and lusters are designed for retrofit replacement of incandescent lamps, and are particularly attractive for chandeliers. They are compatible with fixtures with an E14 holder for candles and E14 or E27 holders for lusters, and are available in either warm white, white or cool daylight color temperatures. LED lamps deliver huge energy savings and minimize maintenance cost. The CorePro LED candles and lusters are perfect for your basic lighting needs. They provide the beautiful light and dependable performance you expect from LED at an affordable price.

Product data

| General Information | |
|---------------------------------------|---------------------|
| Cap-Base | E14 [E14] |
| EU RoHS compliant | Yes |
| Nominal Lifetime (Nom) | 15000 h |
| Switching Cycle | 50000X |
| Technical Type | 4-25W |
| Light Technical | |
| Color Code | 827 [CCT of 2700K] |
| Luminous Flux (Nom) | 250 lm |
| Color Designation | Warm White (WW) |
| Correlated Color Temperature (Nom) | 2700 K |
| Luminous Efficacy (rated) (Nom) | 62.50 lm/W |
| Color Consistency | <6 |
| Color Rendering Index (Nom) | 80 |
| LLMF At End Of Nominal Lifetime (Nom) | 70 % |

| Operating and Electrical | |
|---------------------------------|-------------|
| Input Frequency | 50 to 60 Hz |
| Power (Nom) | 4 W |
| Lamp Current (Nom) | 35 mA |
| Wattage Equivalent | 25 W |
| Starting Time (Nom) | 0.5 s |
| Warm Up Time to 60% Light (Nom) | 0.5 s |
| Power Factor (Nom) | 0.4 |
| Voltage (Nom) | 220-240 V |
| Temperature | |
| T-Case Maximum (Nom) | 75 °C |
| Controls and Dimming | |
| Dimmable | No |

CorePro LED candles and lusters

Mechanical and Housing

| | |
|-------------|-------|
| Bulb Finish | Clear |
|-------------|-------|

Approval and Application


| | |
|-------------------------------|-------|
| Energy Efficiency Label (EEL) | A+ |
| Energy Consumption kWh/1000 h | 4 kWh |

Product Data

| | |
|-------------------|-----------------|
| Full product code | 871869650757500 |
|-------------------|-----------------|

| | |
|---------------------------------|--|
| Order product name | Corepro Candle ND 4-25W E14 827 B35 CL |
| EAN/UPC - Product | 8718696507575 |
| Order code | 929001142202 |
| Numerator - Quantity Per Pack | 1 |
| Numerator - Packs per outer box | 10 |
| Material Nr. (12NC) | 929001142202 |
| Net Weight (Piece) | 0.040 kg |

Dimensional drawing


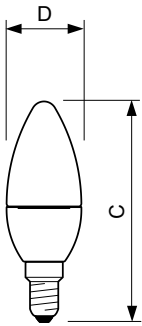


LED ND 4-25W E14 827 220-240V B35 CL

Product

Corepro Candle ND 4-25W E14 827 B35 CL

Photometric data

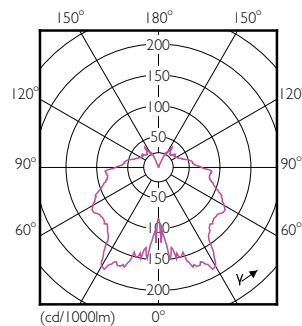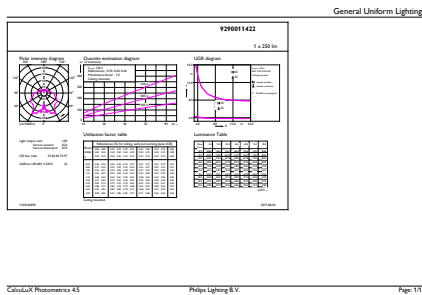

CorePro LEDcandle 4-25W E14 827 CL B35

CorePro LEDcandle 4-25W E14 827 CL B35

CorePro LED candles and lusters

Photometric data



SDPO_LEDCL_0003-Spectral Power distribution

Lifetime



LEDbulb 60W E14 827 FR B38



LEDbulb 60W E14 827 FR B38

