



# Classic filament LED candles and lusters

## Classic LEDCandle D 2.7-25W B35 E14 827 CL

Featuring a classic heritage design, Classic filament LED candles and lusters combine the familiar shapes of classic incandescent candle or luster with the benefits of the long lasting LED technology. They deliver beautiful, decorative warm-white light while saving around 90% on energy costs compared with traditional light candles and lusters.

### Product data

| General Information                   |                     |
|---------------------------------------|---------------------|
| Cap-Base                              | E14 [ E14]          |
| EU RoHS compliant                     | Yes                 |
| Nominal Lifetime (Nom)                | 15000 h             |
| Switching Cycle                       | 20000X              |
| Technical Type                        | 2.7-25W             |
| Light Technical                       |                     |
| Color Code                            | 827 [ CCT of 2700K] |
| Luminous Flux (Nom)                   | 250 lm              |
| Color Designation                     | Warm White (WW)     |
| Correlated Color Temperature (Nom)    | 2700 K              |
| Luminous Efficacy (rated) (Nom)       | 92.59 lm/W          |
| Color Consistency                     | <6                  |
| Color Rendering Index (Nom)           | 80                  |
| LLMF At End Of Nominal Lifetime (Nom) | 70 %                |
| Operating and Electrical              |                     |
| Input Frequency                       | 50 to 60 Hz         |
| Power (Nom)                           | 2.7 W               |


| Lamp Current (Nom)              | 12 mA     |
|---------------------------------|-----------|
| Wattage Equivalent              | 25 W      |
| Starting Time (Nom)             | 0.5 s     |
| Warm Up Time to 60% Light (Nom) | 0.5 s     |
| Power Factor (Nom)              | 0.7       |
| Voltage (Nom)                   | 220-240 V |
| Temperature                     |           |
| T-Case Maximum (Nom)            | 40 °C     |
| Controls and Dimming            |           |
| Dimmable                        | Yes       |
| Mechanical and Housing          |           |
| Bulb Finish                     | Clear     |
| Approval and Application        |           |
| Energy Efficiency Label (EEL)   | A++       |
| Energy Consumption kWh/1000 h   | 3 kWh     |

Classic filament LED candles and lusters

| Product Data                  |                                            |
|-------------------------------|--------------------------------------------|
| Full product code             | 871869670980100                            |
| Order product name            | Classic LEDCandle D 2.7-25W B35 E14 827 CL |
| EAN/UPC - Product             | 8718696709801                              |
| Order code                    | 929001332002                               |
| Numerator - Quantity Per Pack | 1                                          |

|                                 |              |
|---------------------------------|--------------|
| Numerator - Packs per outer box | 10           |
| Material Nr. (12NC)             | 929001332002 |
| Net Weight (Piece)              | 0.014 kg     |


Dimensional drawing

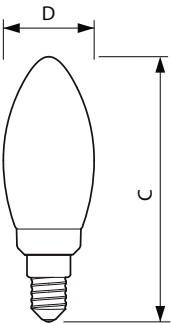


Candle B35 230V3-25W 250lm 2700K D Clear

| Product                                    | D     | C      |
|--------------------------------------------|-------|--------|
| Classic LEDCandle D 2.7-25W B35 E14 827 CL | 35 mm | 103 mm |

 
Photometric data



LEDbulb, Bulb A21 14W, 18W 2200-2700K

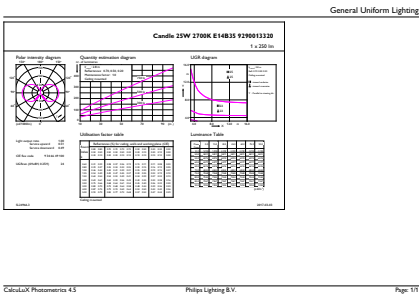


LEDbulb 25W E14 827 CL B35

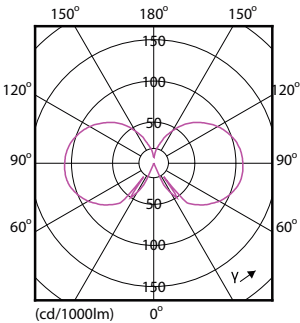


LEDbulb 25W E14 827 CL B35

Classic filament LED candles and lusters

Lifetime

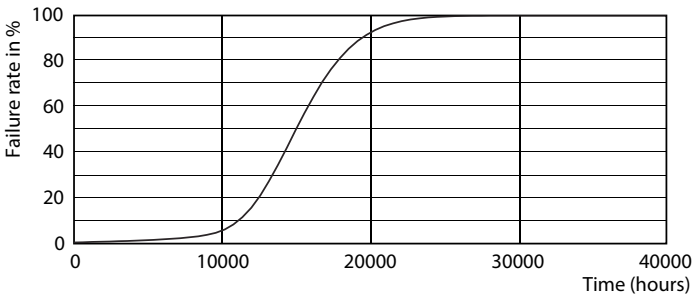

LEDbulb 40W E27 827 CL A60 D

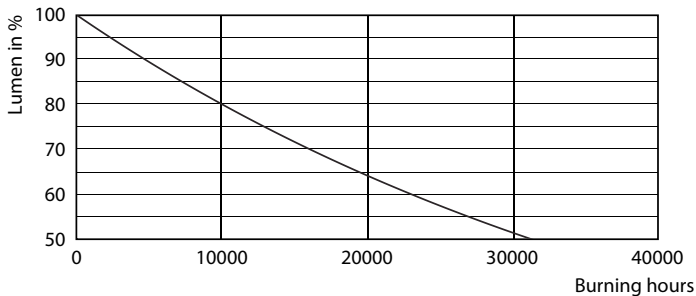

LEDbulb 40W E27 827 CL A60 D

