

# Flat Flexible Cables - 1mm Pitch **multicomp** PRO

## Materials

- Insulator : PET(White)
- Support Tape : PET(Blue)
- Contact : Brass Tin Plating

**RoHS  
Compliant**


## Recommended Storage Conditions

- Temperature : 15°C to 25°C
- Humidity : 30RH% to 60RH%


## Length Tolerance

50mm  $\pm 3\%$ , 51mm to 200mm  $\pm 5\%$ , 305mm  $\pm 10\%$

Dimensions	
Type "2"	Type "3"
S1=4 $\pm 1$	S1=5 $\pm 1$
S2=4 $\pm 1$	S2=5 $\pm 1$
D1=8 $\pm 2$	D1=10 $\pm 2$
D2=8 $\pm 2$	D2=10 $\pm 2$

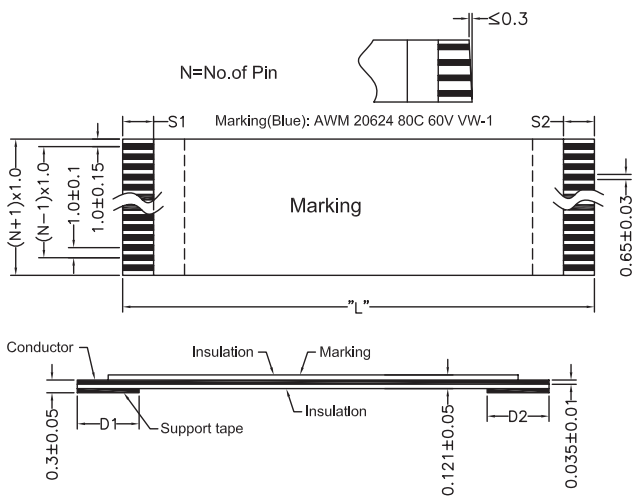

**Style A**

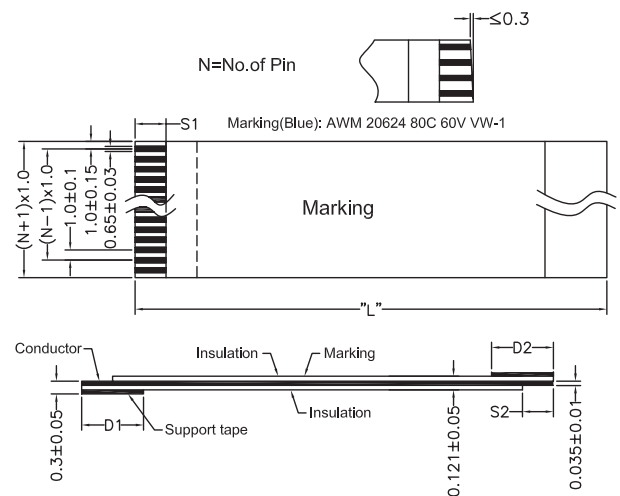

**Style B**

## Part Number Table

Ways	Length	Dimensions	Style "A"	Style "B"
4	50	Type 3	MP-FFCA10040503A	MP-FFCA10040503B
4	100	Type 3	MP-FFCA10041003A	MP-FFCA10041003B
4	152	Type 3	MP-FFCA10041523A	MP-FFCA10041523B
4	200	Type 3	MP-FFCA10042003A	MP-FFCA10042003B

Newark.com/multicomp-pro  
Farnell.com/multicomp-pro  
Element14.com/multicomp-pro

**multicomp** PRO

# Flat Flexible Cables - 1mm Pitch **multicomp** PRO

Ways	Length	Dimensions	Style "A"	Style "B"
5	50	Type 3	MP-FFCA10050503A	MP-FFCA10050503B
5	200	Type 3	MP-FFCA10052003A	MP-FFCA10052003B
6	50	Type 3	MP-FFCA10060503A	MP-FFCA10060503B
6	100	Type 3	MP-FFCA10061003A	MP-FFCA10061003B
6	200	Type 3	MP-FFCA10062003A	-
8	50	Type 3	-	MP-FFCA10080503B
8	100	Type 3	MP-FFCA10081003A	MP-FFCA10081003B
8	200	Type 3	MP-FFCA10082003A	-
9	50	Type 3	-	MP-FFCA10090503B
9	200	Type 3	MP-FFCA10092003A	-
10	50	Type 3	MP-FFCA10100503A	-
10	100	Type 3	MP-FFCA10101003A	MP-FFCA10101003B
10	152	Type 3	MP-FFCA10101523A	-
10	200	Type 3	-	MP-FFCA10102003B
12	100	Type 3	MP-FFCA10121003A	-
14	50	Type 3	MP-FFCA10140503A	-
14	100	Type 3	MP-FFCA10141003A	MP-FFCA10141003B
15	50	Type 3	MP-FFCA10150503A	MP-FFCA10150503B
15	100	Type 3	MP-FFCA10151003A	MP-FFCA10151003B
15	152	Type 3	-	MP-FFCA10151523B
15	200	Type 3	MP-FFCA10152003A	MP-FFCA10152003B
16	50	Type 3	MP-FFCA10160503A	-
16	100	Type 3	MP-FFCA10161003A	MP-FFCA10161003B
18	100	Type 3	MP-FFCA10181003A	-
20	50	Type 3	MP-FFCA10200503A	-
20	100	Type 3	MP-FFCA10201003A	MP-FFCA10201003B
20	200	Type 3	MP-FFCA10202003A	MP-FFCA10202003B
24	100	Type 3	MP-FFCA10241003A	-
24	200	Type 3	MP-FFCA10242003A	-
26	200	Type 3	MP-FFCA10262003A	MP-FFCA10262003B
30	50	Type 3	-	MP-FFCA10300503B
30	100	Type 3	MP-FFCA10301003A	MP-FFCA10301003B
2	305	Type 2	MP-FFCA10023052A	MP-FFCA10023052B
3	305	Type 2	MP-FFCA10033052A	MP-FFCA10033052B
4	305	Type 2	MP-FFCA10043052A	MP-FFCA10043052B
5	305	Type 2	MP-FFCA10053052A	MP-FFCA10053052B
6	152	Type 2	MP-FFCA10061522A	-
6	305	Type 2	MP-FFCA10063052A	MP-FFCA10063052B
7	305	Type 2	MP-FFCA10073052A	MP-FFCA10073052B

Newark.com/multicomp-pro  
 Farnell.com/multicomp-pro  
 Element14.com/multicomp-pro

**multicomp** PRO

# Flat Flexible Cables - 1mm Pitch **multicomp** PRO

Ways	Length	Dimensions	Style "A"	Style "B"
8	50	Type 2	MP-FFCA10080502A	-
8	152	Type 2	MP-FFCA10081522A	-
8	305	Type 2	MP-FFCA10083052A	MP-FFCA10083052B
9	305	Type 2	MP-FFCA10093052A	MP-FFCA10093052B
10	51	Type 2	MP-FFCA10100512A	-
10	152	Type 2	MP-FFCA10101522A	-
10	305	Type 2	MP-FFCA10103052A	MP-FFCA10103052B
11	305	Type 2	MP-FFCA10113052A	MP-FFCA10113052B
12	152	Type 2	MP-FFCA10121522A	-
12	305	Type 2	MP-FFCA10123052A	MP-FFCA10123052B
13	305	Type 2	MP-FFCA10133052A	MP-FFCA10133052B
14	152	Type 2	MP-FFCA10141522A	-
14	305	Type 2	MP-FFCA10143052A	MP-FFCA10143052B
15	305	Type 2	MP-FFCA10153052A	MP-FFCA10153052B
16	51	Type 2	MP-FFCA10160512A	-
16	152	Type 2	MP-FFCA10161522A	-
16	305	Type 2	MP-FFCA10163052A	MP-FFCA10163052B
17	305	Type 2	MP-FFCA10173052A	MP-FFCA10173052B
18	305	Type 2	MP-FFCA10183052A	MP-FFCA10183052B
19	305	Type 2	MP-FFCA10193052A	MP-FFCA10193052B
20	51	Type 2	MP-FFCA10200512A	-
20	152	Type 2	MP-FFCA10201522A	-
20	305	Type 2	MP-FFCA10203052A	MP-FFCA10203052B
22	152	Type 2	MP-FFCA10221522A	-
22	305	Type 2	MP-FFCA10223052A	MP-FFCA10223052B
24	152	Type 2	MP-FFCA10241522A	-
24	305	Type 2	MP-FFCA10243052A	MP-FFCA10243052B
26	152	Type 2	MP-FFCA10261522A	-
26	305	Type 2	MP-FFCA10263052A	MP-FFCA10263052B
28	305	Type 2	MP-FFCA10283052A	MP-FFCA10283052B
30	152	Type 2	MP-FFCA10301522A	-
30	305	Type 2	MP-FFCA10303052A	MP-FFCA10303052B
40	305	Type 2	MP-FFCA10403052A	MP-FFCA10403052B

**Important Notice :** This data sheet and its contents (the "Information") belong to the members of the AVNET group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. Multicomp Pro is the registered trademark of Premier Farnell Limited 2019.

Newark.com/multicomp-pro  
 Farnell.com/multicomp-pro  
 Element14.com/multicomp-pro

**multicomp** PRO