

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0524352171
Status: Active
Overview: Easy-On FFC FPC Connectors
Description: Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 21 Circuits, Gold Plating

Documents:

- | | |
|---------------------------------|--|
| Drawing (PDF) | Product Guide (PDF) |
| 3D Model | RoHS Certificate of Compliance (PDF) |
| 3D Model (PDF) | Reference Guide (PDF) |
| Datasheet (PDF) | |

Agency Certification

UL E29179

General

Product Family	FFC/FPC Connectors
Series	52435
Overview	Easy-On FFC FPC Connectors
Product Name	Easy-On
Series Name	Slider
UPC	822350132909


Physical

Actuator Type	Slider
Circuits (Loaded)	21
Contact Position	Top
Durability (mating cycles max)	20
Flammability	94V-0
Mated Height	2.00mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	Nylon
Net Weight	285.506/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FFC/FPC

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V

Material Info

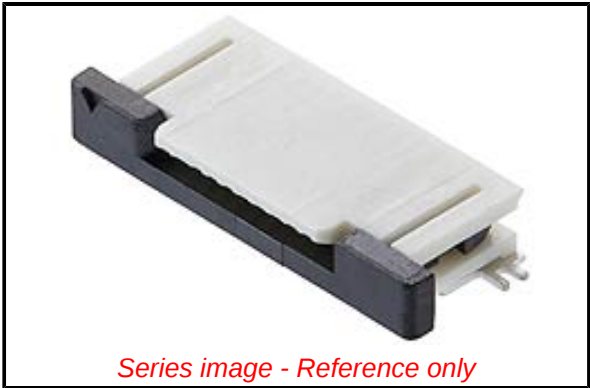

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2020)4578-DC (25
June 2020)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

52435 Series

Mates With

Premo-Flex FFC Cable [15020](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION