

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0685080811](#)
Status: **Active**
Description: 1.02mm Tab, Wire-to-Wire Housing, Female, 8 Circuits, with TPA, Black

Documents:

3D Model	Product Specification PS-104000-001-013 (PDF)
Drawing (PDF)	Packaging Specification PK-68508-001-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Crimp Housings
Series	68508
Application	Power, Wire-to-Wire
Product Name	N/A
UPC	756054305812


Physical

Circuits (maximum)	8
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	7.413/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	2.50mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +80°C

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-68508-001-001
Product Specification	PS-104000-001-013
Sales Drawing	SD-68508-002

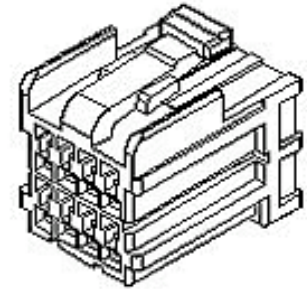

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/71/2019 (16 July
2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Not Relevant

Compliant

Not Contained

Search Parts in this Series

[68508 Series](#)

Mates With

[685070811](#) , [685070821](#)

Use With

[506609001](#) , [685100883](#) , [506541001](#)