

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0355631615](#)  
**Status:** **Active**  
**Description:** 1.02mm Tab Wire-to-Board Housing, Female, 16 Circuits

**Documents:**

<a href="#">3D Model</a>	<a href="#">Product Specification PS-104000-001-013 (PDF)</a>
<a href="#">Drawing (PDF)</a>	<a href="#">Packaging Specification PK-35563-001-001 (PDF)</a>
<a href="#">3D Model (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**General**

Product Family	Crimp Housings
Series	35563
Application	Power, Wire-to-Board
Product Name	N/A
UPC	756054251034

**Physical**

Circuits (maximum)	16
Color - Resin	Gray, Natural
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	No
Material - Resin	Polyester
Net Weight	3.800/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.50mm
Stackable	No
Temperature Range - Operating	-30° to +85°C


**Electrical**

Current - Maximum per Contact	10.0A
-------------------------------	-------

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification	PK-35563-001-001
Product Specification	PS-104000-001-013
Sales Drawing	SD-35563-001

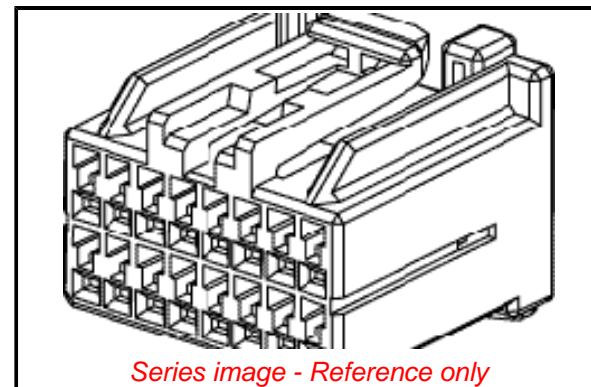

**EU ELV**

**Compliant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
ED/71/2019 (16 July  
2019)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Not Relevant

Compliant

Not Contained

**Search Parts in this Series**

[35563 Series](#)

**Mates With**

[68145](#)

**Use With**

Tab Type Female Crimp Terminal [50654](#)