

JST

Hand crimping tool
Type: WC-710

Features

Parallel action
operation

Ratchet release

Easy readjustment
of load

Contact locator with
insulation-stop

Precisely ground
profiles

Ergonomic soft grips
colour: green


Fully recyclable

Applicable terminal:
< >PS-51T-187



Cross section range:
Profile 1: 0.5mm² / 0.75mm²
Profile 2: 1.25mm²
Profile 3: 2.00mm²

Crimp height specification
0.5mm² - 1.10mm
0.75mm² - 1.20mm
1.25mm² - 1.30mm
2.00mm² - 1.50mm

Operating instructions see overleaf

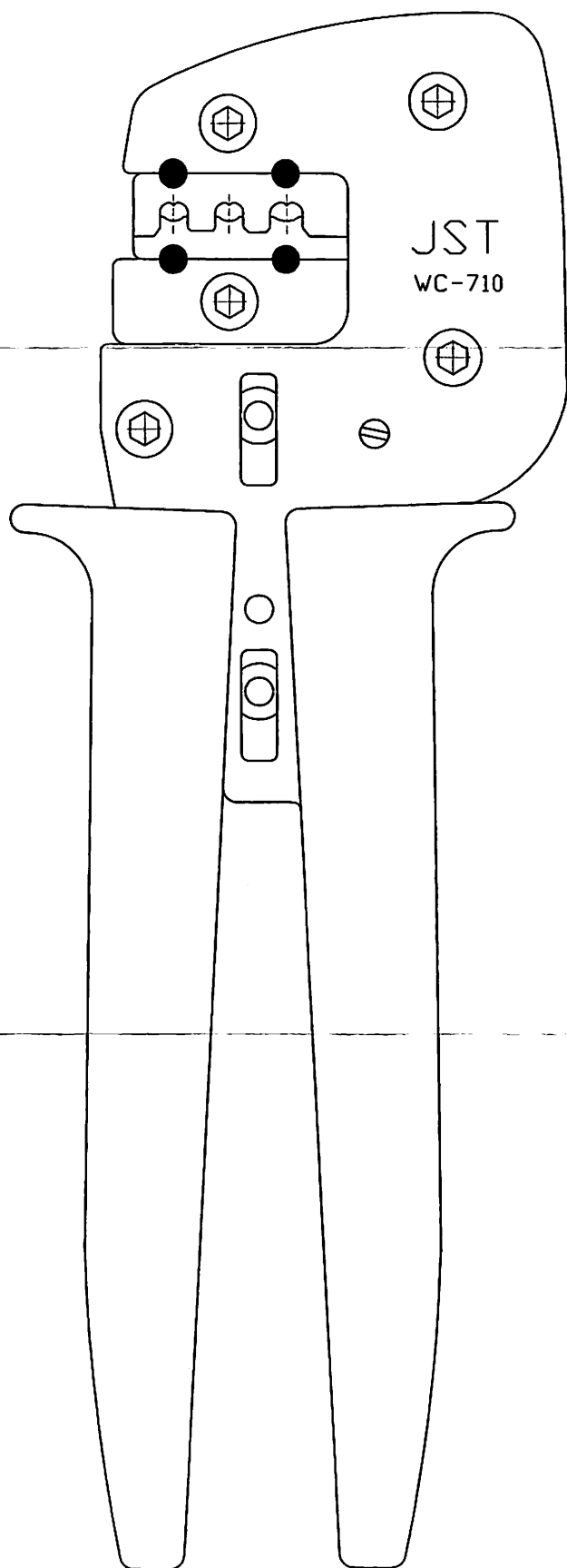

OPERATION INSTRUCTIONS

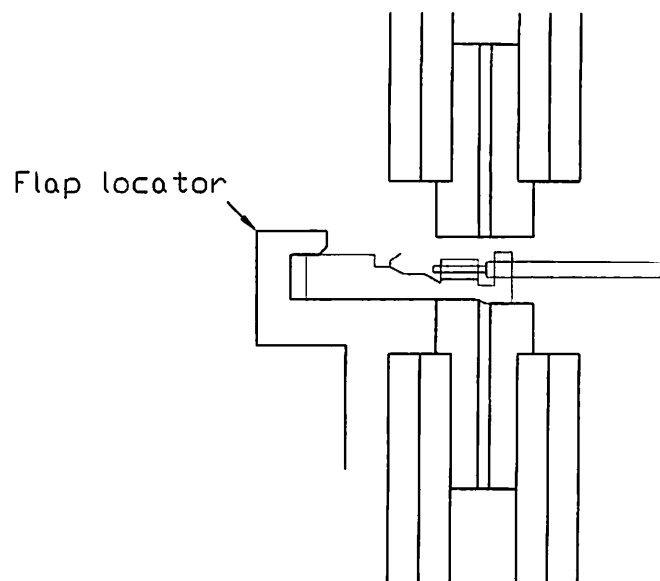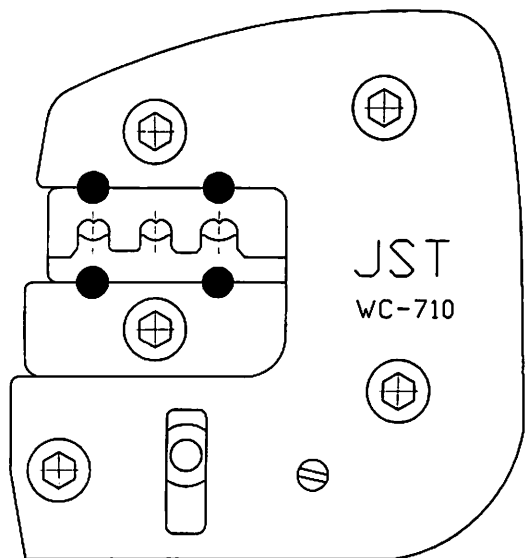

1. Open flap locator and insert contact up to stop.
2. Close flap locator.
3. Close handtool until first ratchet.
4. Insert wire.
5. Close handtool until the ratchet releases.
6. Open flap locator and carefully remove the wire.