


Dial Test Indicators

Metric

Roebuck

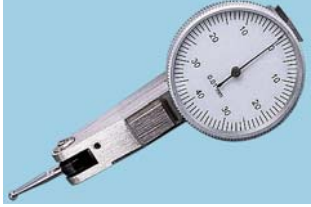

Dial diameter 32mm. Satin chrome indicator body with dovetail on all three sides. Automatic reverse mechanism. Adjustable bezel for easy reading, 250° lever position. Fully jewelled movements. 2mm diameter ball anvil stylus 14.5mm long. Accuracy to DIN 2270 and BS2795.

490408

Range	Graduations	Order Code	Price Each
0 - 0.8mm	0.01mm	137-5881	