


# Sil-Pad® Configurations



## Metric Measurements

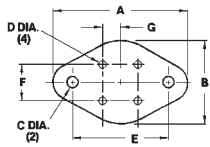


4 Lead TO-66	Part Number Suffix	"A"	"B"	"C"	Dimensions "D"	"E"	"F"	"G"
	-84	33.32	19.35	3.56	1.57	24.38	5.08	2.54

Plastic Power	Part Number Suffix	"A"	"B"	Dimensions "C"	"D"	Part Number Suffix	"A"	"B"	Dimensions "C"	"D"	
Various (Clip Mount)	-35	18.03	12.70	4.06	3.58	Various -104	25.40	19.05	7.62	3.56	
	-43	19.05	12.70			Various -107	20.57	23.11	4.32	3.73	
TO-126	-50	11.10	7.92	3.56	2.36	Various -110	24.99	19.99			
Various	-51	17.45	14.27	5.54	3.18	Various -114	21.01	24.00	5.00	3.81	
Various	-52	21.72	16.00	5.84	2.36	Various -116	21.72	16.00	5.79	3.10	
TO-220	-54	19.05	12.70	4.75	3.73	Various -117	21.01	18.01	6.50	3.20	
TO-202	-55	15.49	14.22	6.22	3.18	Various -118	19.00	14.00	5.51	3.20	
Various	-56	21.72	14.27	5.54	3.18	Various -119	11.10	7.90	3.61	2.79	
TO-220	-58	19.05	12.70	4.75	3.18	Various -120	18.49	11.99	3.99	2.49	
TO-126	-60	11.10	7.92	3.56	3.10	TO-3P	-122	28.96	20.57	9.02	3.73
Various	-61	19.05	10.41	5.72	3.96	Various -126	24.00	19.00	6.50	4.11	
TO-220	-62	19.05	15.24	6.10	3.81	Various -128	24.99	42.01	8.00	3.99	
Various	-63	19.05	15.24	6.10	2.92	Various -131	18.01	13.00	4.50	3.10	
Various	-64	12.70	9.78	4.32	3.05	Various -132	11.99	8.00	3.99	3.20	
TO-218	-68	28.58	15.88	5.08	3.68	Various -133	22.00	18.01	6.50	3.20	
Various	-70	35.81	20.57	9.02	3.73	Various -134	24.00	18.01	5.79	3.20	
Various	-90	21.84	18.80	5.08	4.06	Various -136	31.75	25.40			
Various	-102	22.00	16.51	5.51	3.61	Various -137	31.75	25.40	6.55	3.23	
Various	-103	19.05	20.32	3.81	4.06	Various -138	31.75	25.40	6.55	3.76	


TO-220

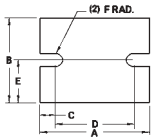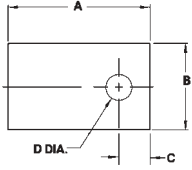


Power Module	Number Suffix	"A"	"B"	Dimensions "C"	"D"	"E"	"F"
	-67	38.10	22.86	3.81	30.48	11.43	1.90
	-101	63.50	50.80	8.74	46.02	25.40	3.96

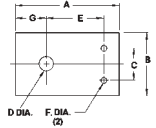


Plastic Power	Part Number Suffix	"A"	"B"	"C"	Dimensions "D"	"E"	"F"	"G"
	-57	23.11	12.70	5.08	3.18	14.73	1.17	6.73
	-89	24.97	19.05	10.97	3.96	16.89	2.57	5.51

 


Plastic Power	Part Number Suffix	"A"	"B"	"C"	Dimensions "D"	"E"	"F"	"G"	"H"
	-66	25.40	12.70	5.08	3.58	15.90	1.17	5.56	0.81

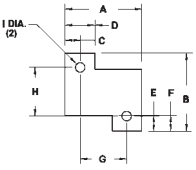

Power Resistors	Part Number Suffix	"A"	"B"	"C"	"D"	Dimensions "E"	"F"	"G"	"H"	"I"
RH-25	-94	30.15	30.61	5.94	11.91	5.38	3.96	18.26	19.84	3.56
RH-50	-95	53.16	32.13	6.73	13.46	5.33	6.48	39.70	21.46	3.56
RH-5	-96	18.42	19.58	3.56	7.11	3.56	3.96	11.30	12.47	2.36
RH-10	-97	20.45	22.61	3.23	6.35	3.30	4.83	14.00	16.00	3.07
RH-25	-98	29.21	29.97	5.87	10.80	4.83	6.86	17.48	20.32	3.73
RH-50	-99	49.91	31.39	5.03	10.26	3.35	6.68	39.85	24.69	3.30

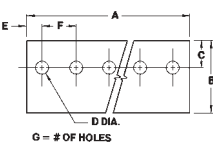

TO-220 Multiples	Part Number Suffix	"A"	"B"	Dimensions "C"	"D"	"E"	"F"	# of Holes
2 Parts	-34	25.40	19.05	4.75	3.18	6.35	12.70	2
3 Parts	-36	38.10	19.05	4.75	3.18	6.35	12.70	3
	-37	50.80	19.05	4.75	3.18	6.35	12.70	4
	-38	63.50	19.05	4.75	3.18	6.35	12.70	5
	-39	76.20	19.05	4.75	3.18	6.35	12.70	6
	-40	88.90	19.05	4.75	3.18	6.35	12.70	7
	-41	101.60	19.05	4.75	3.18	6.35	12.70	8

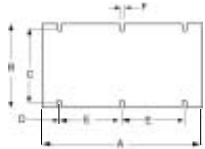


Power Module	Part Number Suffix	"A"	"B"	Dimensions "C"	"D"	"E"	"F"
	-108	116.84	60.96	53.97	12.70	45.72	3.18
	-140	116.8	61.00	53.30	12.70	45.70	3.80
	-141	57.90	61.00	53.40	12.40	16.50	3.80
	-142	57.91	36.83	32.26	12.45	16.50	3.30


ORDERING

# Sil-Pad® Configurations


## Metric Measurements

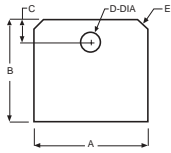


Part Number	Dimensions
Suffix	"A" "B" "C" "D" "E"
-124	22.15 20.07 4.06 3.76 3.0 x 45°
-125	22.00 19.99 3.99 3.91 2.0 x 45°

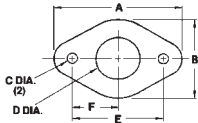


Part Number	Dimensions
Suffix	"A" "B" "C" "D" "E" "F"
-93	34.29 20.32 3.56 10.16 24.38 12.19

 


Part Number	Dimensions
Suffix	"A" "B"
Various	-19 12.95 3.56
DO-4	-20 12.95 5.08
DO-5	-21 20.32 6.60
DO-4 (oversized)	-22 15.88 5.08
DO-5 (oversized)	-25 25.40 6.60
Various	-26 20.62 3.68
Various	-27 20.62 2.92
Various	-28 25.40 3.56
Various	-32 38.10 12.70

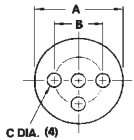


Part Number	Dimensions
Suffix	"A" "B" "C"
-08	27.00 17.53 4.83

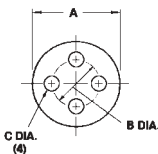


Part Number	Dimensions
Suffix	"A" "B" "C"
TO-5, 3 Holes	-09 9.14 5.08 1.02
TO-18, 3 Holes	-12 6.35 2.54 0.91
TO-18, 4 Holes	-13 6.35 2.54 0.91
TO-5, 4 Holes	-33 9.14 5.08 1.02
TO-5, 3 Holes	-44 9.91 5.08 1.02
TO-5, 4 Holes	-45 9.91 5.08 1.02

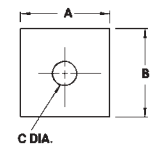


Part Number	Dimensions
Suffix	"A" "B" "C"
-46	31.75 31.75 5.08
-47	28.58 28.58 3.56
-48	25.40 25.40 4.75

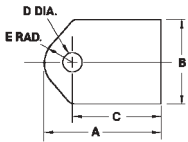


Part Number	Dimensions
Suffix	"A" "B" "C" "D" "E"
Clip Mount	-42 24.99 19.99 5.21
TIP-36 Plastic Tip	-53 21.97 16.51 16.51 3.56 5.21
TO-3P	-65 32.00 19.99 24.99 3.61 5.21
Plastic Clip	-73 24.99 19.99 17.98 3.61 5.21

 


Part Number	Dimensions
Suffix	"A" "B" "C" "D" "E" "F" "G"
-100	63.75 32.00 16.00 7.75 48.26 5.21 5.21
-123	41.00 27.99 14.00 3.99 30.99 3.00 3.00

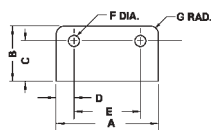

Part Number	Dimensions
Suffix	"A" "B" "C" "D" "E" "F" "G"
-105	36.83 21.29 15.54 6.22 24.38 4.32 3.05

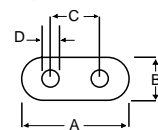


Part Number	Dimensions
Suffix	"A" "B" "C" "D"
-115	11.99 5.00 4.90 0.79

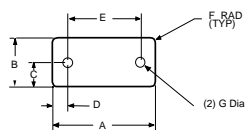


Part Number	Dimensions
Suffix	"A" "B" "C" "D" "E" "F" "G"
-109	34.29 16.31 8.15 4.95 24.38 1.52 3.18

# Sil-Pad® Configurations


## Metric Measurements

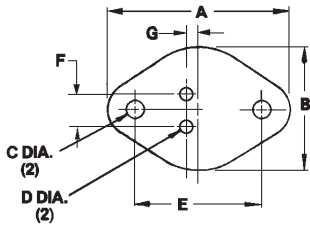


TO-3 Style	Part Number Suffix	"A"	"B"	"C"	Dimensions "D"		"E"	"F"	"G"
	-02	45.21	31.75	3.56	2.36		30.15	10.92	1.83
	-03	39.70	26.67	3.56	2.03		30.15	10.92	1.83
	-04	41.91	28.96	3.10	1.57		30.15	10.92	1.83
	-05	41.91	28.96	3.56	2.36		30.15	10.92	1.83
	-06	41.91	28.96	4.19	1.57		30.15	10.92	1.83
	-07	45.21	31.75	4.19	2.39		30.15	10.92	1.83
	-10	36.58	25.40	3.56	1.90		24.38	5.08	2.54
	-11	33.32	19.35	3.56	1.57		24.38	5.08	2.54
	-15	45.21	31.75	3.56	1.17		30.15	10.92	1.83
	-16	52.58	39.62	3.10	1.57		30.15	10.92	1.83
	-17	41.91	28.96	3.56	1.17		30.15	10.92	1.83
	-18	39.70	26.67	3.56	3.56		30.15	10.92	1.83
	-23	40.46	27.94	3.96	1.57		30.15	10.92	1.83
	-24	43.18	30.15	3.96	1.57		30.15	10.92	1.83
	-29	41.91	27.05	3.56	1.17		30.15	10.92	1.83
	-30	31.75	17.78	3.56	1.57		24.38	5.08	2.54
	-31	34.92	20.96	3.56	1.57		24.38	5.08	2.54
	-59 Leadless	41.91	28.96	4.19			30.15		
	-112	45.21	31.70	4.19	1.60		30.10	10.90	1.85
	-113	39.70	26.70	4.19	2.01		30.10	10.90	1.85
	-127	33.20	20.80	4.19	1.60		23.09	5.99	1.55
	-129	42.01	27.00	3.51	1.50		30.00	11.00	1.80
	-135	41.91	29.01	4.19	3.61		30.15	10.90	1.83

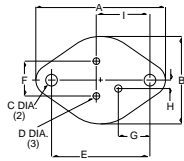


3 Lead TO-3	Part Number Suffix	"A"	"B"	"C"	Dimensions "D"		"E"	"F"	"G"	"H"	"I"
	-92	41.91	28.96	3.56	2.36		30.15	10.92	10.16	3.94	18.24

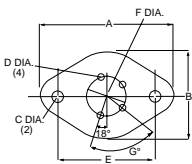


4 Lead TO-3	Part Number Suffix	"A"	"B"	"C"	"D"	"E"	"F"	"G"
	-86	39.62	26.67	3.96	2.03	29.72	11.94	72°
	-87	39.70	26.67	3.96	1.60	30.15	11.94	72°

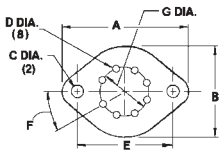


8 Lead TO-3	Part Number Suffix	"A"	"B"	"C"	"D"	"E"	"F"	"G"
	-88	42.04	30.15	3.96	1.52	30.15	40°	12.70

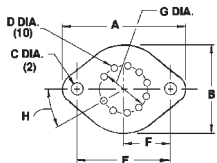


10 Lead TO-3	Part Number Suffix	"A"	"B"	"C"	"D"	"E"	"F"	"G"	"H"
	-91	41.91	28.96	4.19	1.02	30.15	15.06	12.70	32.7°

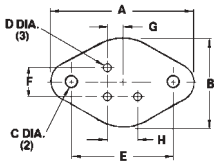

3 Lead TO-66	Part Number Suffix	"A"	"B"	"C"	"D"	"E"	"F"	"G"	"H"
	-85	32.38	19.05	3.96	2.54	24.38	5.08	2.54	5.08

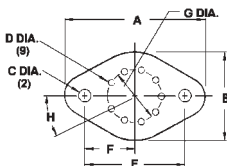

9 Lead TO-66	Part Number Suffix	"A"	"B"	"C"	"D"	"E"	"F"	"G"	"H"
	-83	36.58	25.40	3.56	1.40	24.38	12.19	8.26	36°

 

Power Module	Part Number Suffix	"A"	"B"	"C"	"D"	"E"
	-130	40.64	12.19	4.19	30.40	6.10