

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2153232062

Status:


Active

Overview:

Mini-Fit Family Power Connectors

Description:

Mini-Fit Jr. Male-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, Single Row, 300.00mm Length, Gold (Au) Plating, 6 Circuits, Black

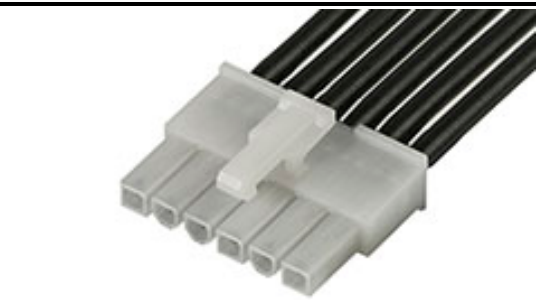

Series image - Reference only

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Datasheet \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	215323
Application	Power, Wire-to-Wire
Assembly Configuration	Single Ended Connector
Connector to Connector	Mini-Fit Jr.-to-Pigtail
Overview	Mini-Fit Family Power Connectors
Product Name	Mini-Fit Jr.
Type	Discrete Wire Assembly
UPC	193264597826
Physical	
Cable Length	300.00mm
Circuits (Loaded)	6
Color - Resin	Black
Gender	Male-Pigtail
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	44.062/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	4.20mm
Plating min - Mating	0.762µm
Plating min - Termination	2.032µm
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.80-3.10mm
Wire Size AWG	16
Wire/Cable Type	UL 1015
Electrical	
Current - Maximum per Contact	9.0A
Voltage - Maximum	600V

Material Info

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)4578-DC (25 June 2020)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

215323 Series

Mates With

Mini-Fit Jr. Receptacle Housing [5557](#)

Mini-Fit TPA2 Cable Assembly [145135](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION