

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2153211053

Status:


Active

Overview:

Mini-Fit Family Power Connectors

Description:

Mini-Fit Jr. Female-to-Pigtail Off-the-Shelf (OTS) Cable Assembly, Single Row, 600.00mm Length, Tin (Sn) Plating, 5 Circuits, Black

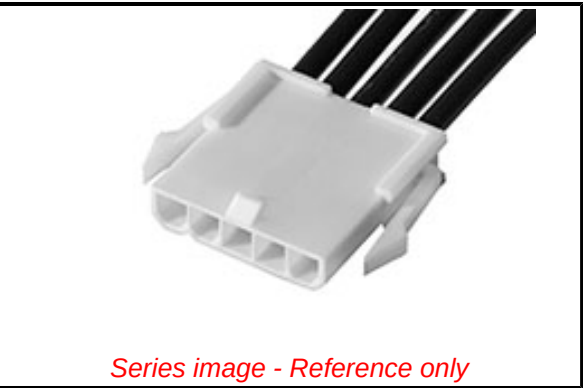

Series image - Reference only

Documents:

[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Datasheet \(PDF\)](#)

General	
Product Family	Cable Assemblies
Series	215321
Application	Power, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Single Ended Connector
Connector to Connector	Mini-Fit Jr.-to-Pigtail
Overview	Mini-Fit Family Power Connectors
Product Name	Mini-Fit Jr.
Type	Discrete Wire Assembly
UPC	193264597055
Physical	
Cable Length	600.00mm
Circuits (Loaded)	5
Color - Resin	Black
Gender	Female-Pigtail
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	67.821/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	4.20mm
Plating min - Mating	0.889µm
Plating min - Termination	0.889µm
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.80-3.10mm
Wire Size AWG	16
Wire/Cable Type	UL 1015
Electrical	
Current - Maximum per Contact	9.0A
Voltage - Maximum	600V
Material Info	
Reference - Drawing Numbers	
Sales Drawing	2153211051-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

Not Relevant

REACH SVHC

Not Contained Per - D(2020)4578-DC (25 June 2020)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

215321 Series

Mates With

Mini-Fit Jr. Headers [469990703](#) , [469990707](#)

Mini-Fit Jr. Plugs [469990657](#) , [469990658](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION