

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0354388000

Status:

Active

Overview:

Automotive Bulb Sockets

Description:

Contact Terminal for PT Bulb Socket, 0.5-0.85mm² Wire

Documents:

Drawing (PDF)

Product Specification PS-35532-001-001 (PDF)

Packaging Specification PK-35438-001-001 (PDF)


RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	35438
Application	Power
Crimp Quality Equipment	Yes
Overview	Automotive Bulb Sockets
Product Name	PT Bulb Socket
UPC	800754777049
Physical	
Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Unplated
Net Weight	0.346/g
Packaging Type	Reel
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.80-2.80mm
Wire Size AWG	N/A
Wire Size mm²	AVS 0.50-0.85

Material Info

Reference - Drawing Numbers

Crimp Specification	CS-35438-8000-003
Packaging Specification	PK-35438-001-001
Product Specification	PS-35532-001-001

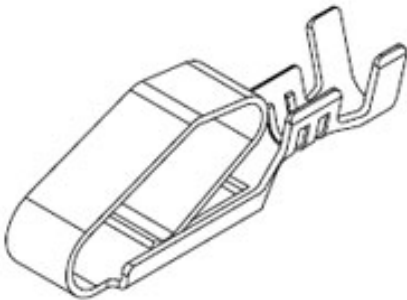

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2020)4578-DC (25 June 2020)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Not Relevant

ELV

Compliant

RoHS Phthalates

Not Contained

Search Parts in this Series

35438 Series

Use With

35532 , 35533 , 35842 , 35843

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Extractor Tool for Crimp Terminals for PT Bulb Socket 0.5-0.85mm² AWG and 2.00mm Bulb-Socket Earth Terminal	638133600
Hand Crimp Tool for Bulb Socket Contact Terminal for 0.50 to 0.85mm² AWG	638194900

This document was generated on 07/14/2020

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION