


**SPECIFICATION  
CONTROL DRAWING  
Crystal Resonator**

FREQUENCY
3.686400MHz

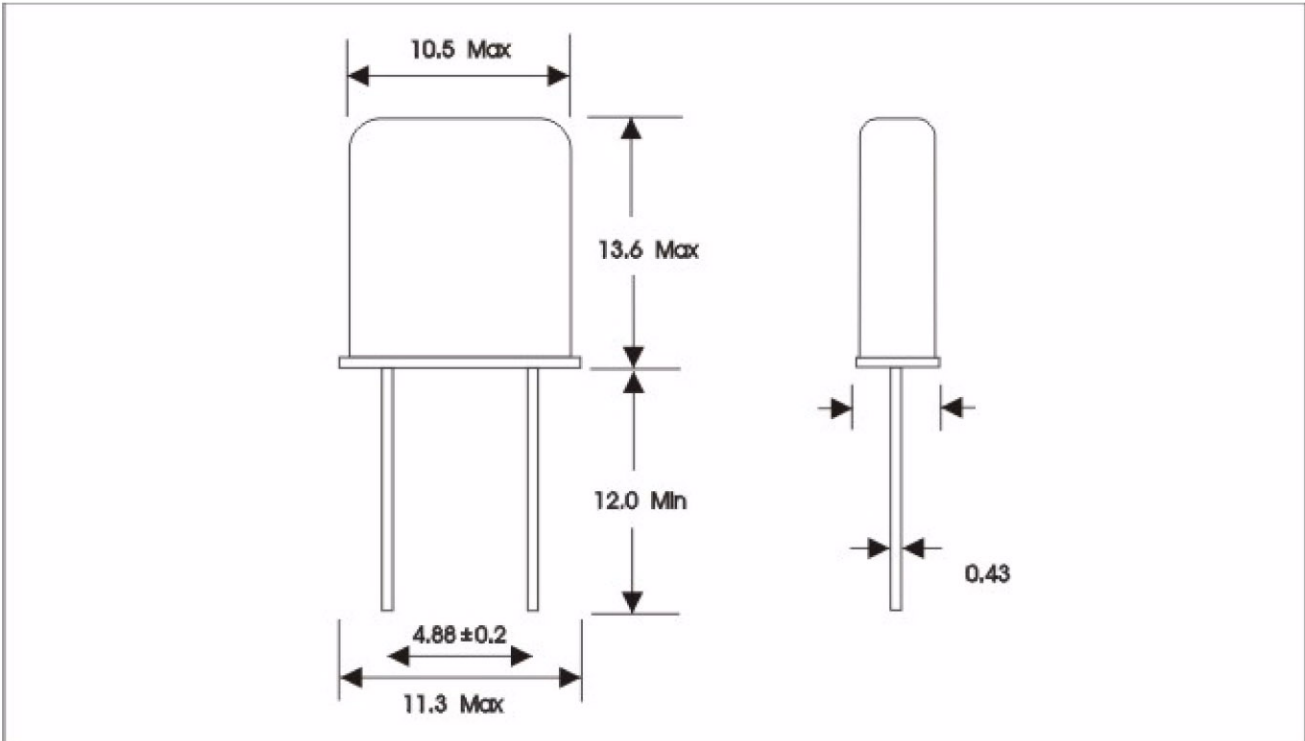

Holder Style	HC-49/U
Mode	Fundamental
Adjustment Tolerance	± 30PPM at 25°C
Temperature Stability	± 50 PPM
Operating Temp. Range	-20°C to +70°C
Load Capacitance	30 pF
ESR	90 Ohm
Marking	Mark AELX005L\FREQ+WWYY

Amdt Date	Change Note	AEL Code
		<b>X3M686400L005</b>
		<b>Issue Ref</b> A