


**SPECIFICATION  
CONTROL DRAWING  
Crystal Resonator**

FREQUENCY
12.288000MHz

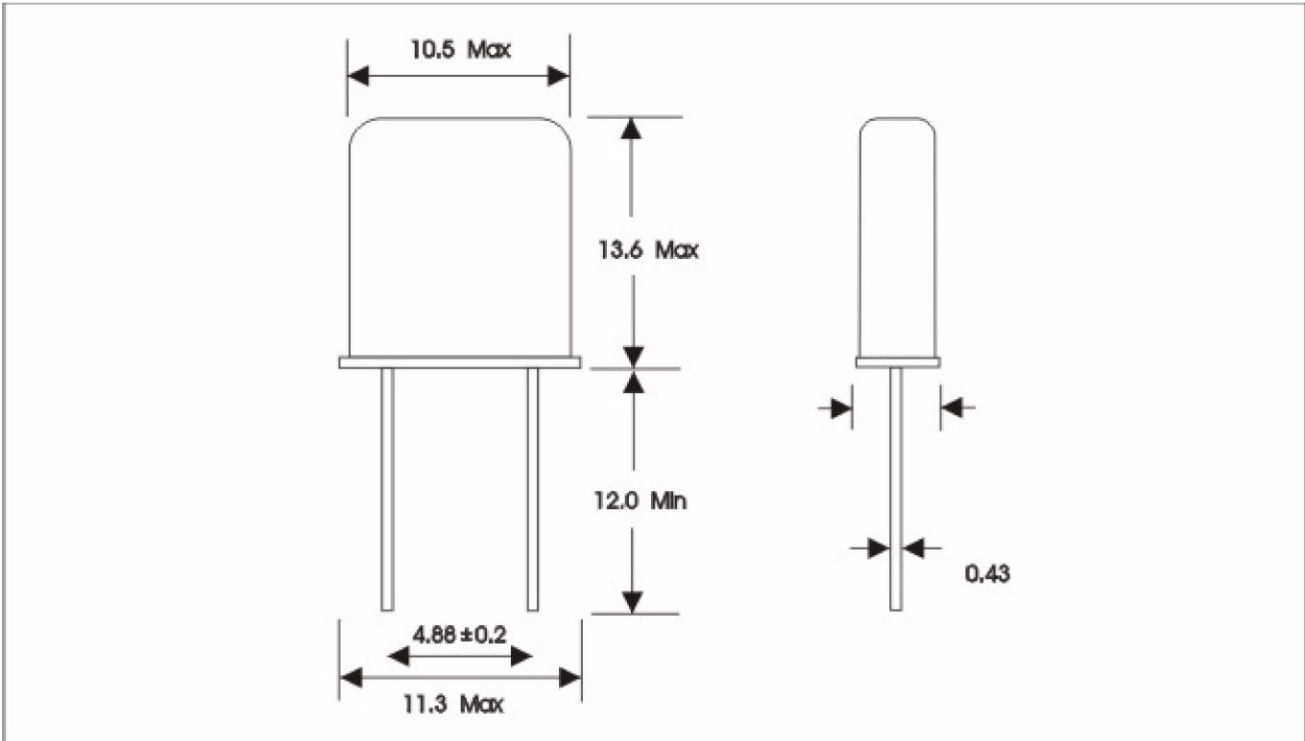

Holder Style	HC-49/U
Mode	Fundamental
Adjustment Tolerance	± 20PPM at 25°C
Temperature Stability	± 50 PPM
Operating Temp. Range	-10°C to +60°C
ESR	25 Ohm
Marking	Mark AELX199L\FREQ+WWYY

Amdt Date	Change Note	AEL Code
		<b>X12M288000L199</b>
		<b>Issue Ref</b> A