




CSB-M1241DB9

► SPLITTERS

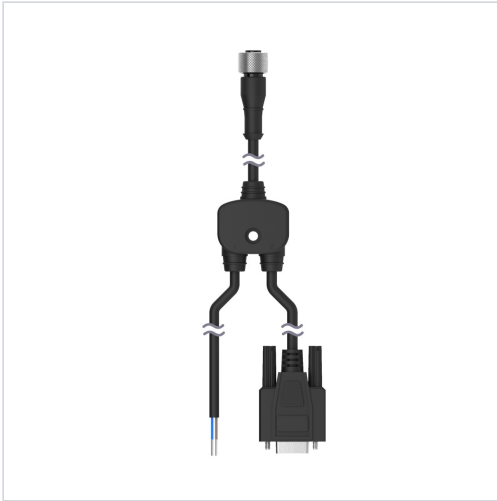

Euro-style Quick Disconnect Splitter Cable

4-Pin Straight female Eurofast 0.30 m (1 ft) Trunk

9-Pin D-SUB Straight Female Eurofast 2m (6.56 ft)
Branch 1

2-Pin Cable 2m (6.56 ft) Branch 2

Nickel Plated Brass Coupling Nuts Black Jacket

Part Number: 809381

SPECIFICATIONS

Number of Contacts	14
Number of Connectors	2
Cable Jacket Material	PVC
Cable Jacket Color	Black
Connector Body Material/Color	PUR Black
Outside Cable Diameter (mm)	5.2
Cordset Length (m)	2.34
Trunk Length (m)	3.05
Shield/No Shield	No Shield
Coupling Material/Color	Nickel Plated Brass
Maximum Temp. (°C)	105

Current Rating (A)	4.0
Minimum Temp. (°C)	-40
Voltage Rating (V)	250 V ac/dc
Primary Connector Type	EURO
Primary Coupling Method	M12 Single Key
Primary Gender	Female
Primary Orientation	Straight
Primary Number of Conductors	4
Primary AWG	22
Splitter Cable Diameter	4.8, 5.2
Splitter Branches: Connector Type	Flying Lead, DB9F
Splitter Branches: Coupling Method	None, DB9 Screw
Splitter Branches: Orientation	-, Straight
Splitter Branches: Number of Conductors	4, 4
Splitter Branches: AWG	22, 22
Splitter Branches Length (m)	2, 2
Splitter Function	Custom
Feature: Hazardous Area	No
Oil/Grease Resistant	No



Banner Engineering Corp. | 9714 Tenth Avenue North | Minneapolis, MN 55441 | United States of America

