

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0150140421](#)
Status: **Active**
Overview: Premo-Flex Flat-Flexible Circuit (FFC) Cable Jumpers
Description: 0.25mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 101.60mm Cable Length, Gold (Au) Plating, 21 Circuits

Documents:

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification 1501400001-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Cable
Series 15014
Crimp Quality Equipment Yes
Overview Premo-Flex Flat-Flexible Circuit (FFC) Cable Jumpers
Product Name Premo-Flex FFC Jumper
UPC 191130093304

Physical

Cable Length 101.60mm
Circuits (Loaded) 21
Material - Plating Mating Gold
Net Weight 1.000/g
Packaging Type Bag
Pitch - Mating Interface 0.25mm
Temperature Range - Operating -40° to +105°C
Wire Size AWG N/A
Wire/Cable Type Flat Flex Cable


Electrical

Current - Maximum per Contact 0.2A
Voltage - Maximum N/A

Material Info

Reference - Drawing Numbers

Product Specification 1501400001-000
Sales Drawing 150140001-000

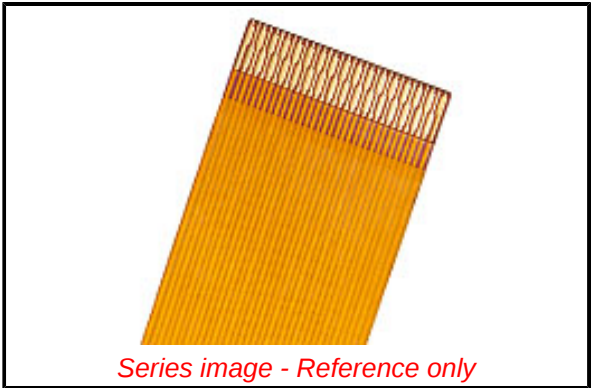

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

15014 Series

Mates With

Easy-On FFC/FPC Connector [5020782110](#) ,
[5020782162](#) , [5033002110](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION