


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2162701060](#)
Status: **Active**
Overview: [Off-the-Shelf Cable Assemblies](#)
Description: SL Female-to-SL Female Off-the-Shelf (OTS) Cable Assembly, Positive Lock, Single Row, 50.00mm Length, Tin (Sn) Plating, 6 Circuits, Black

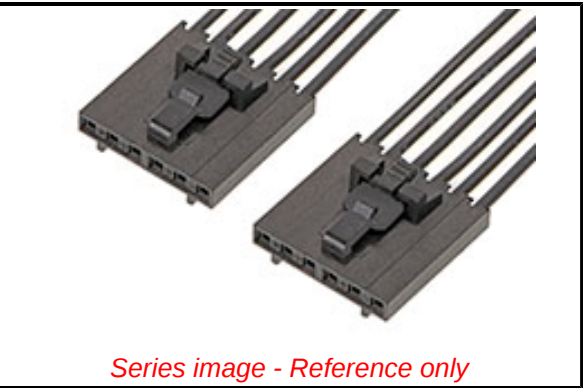

Series image - Reference only

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Datasheet \(PDF\)](#)

General
Product Family Cable Assemblies
Series [216270](#)
Application Signal, Wire-to-Board, Wire-to-Wire
Assembly Configuration Dual Ended Connectors
Connector to Connector SL-to-SL
Overview [Off-the-Shelf Cable Assemblies](#)
Product Name SL
Type Discrete Wire Assembly
UPC 193264730742

Physical
Cable Length 50.00mm
Circuits (Loaded) 6
Color - Resin Black
Gender Female-Female
Lock to Mating Part Yes
Material - Metal Phosphor Bronze
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Polyester Alloy
Net Weight 3.967/g
Number of Rows 1
Packaging Type Bag
Pitch - Mating Interface 2.54mm
Single Ended No
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 1.63mm max.
Wire Size AWG 22
Wire/Cable Type UL 11028

Electrical
Current - Maximum per Contact 3.0A
Voltage - Maximum 600V AC/DC

Material Info

Reference - Drawing Numbers
Sales Drawing 2162701060-000

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)4578-DC (25 June 2020)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[216270 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION