


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2162701032](#)
Status: **Active**
Overview: [Off-the-Shelf Cable Assemblies](#)
Description: SL Female-to-SL Female Off-the-Shelf (OTS) Cable Assembly, Positive Lock, Single Row, 150.00mm Length, Tin (Sn) Plating, 3 Circuits, Black

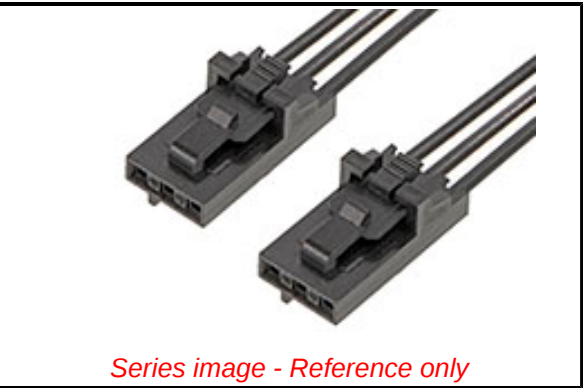

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Datasheet \(PDF\)](#)

General
Product Family Cable Assemblies
Series [216270](#)
Application Signal, Wire-to-Board, Wire-to-Wire
Assembly Configuration Dual Ended Connectors
Connector to Connector SL-to-SL
Overview [Off-the-Shelf Cable Assemblies](#)
Product Name SL
Type Discrete Wire Assembly
UPC 193264730612

Physical
Cable Length 150.00mm
Circuits (Loaded) 3
Color - Resin Black
Gender Female-Female
Lock to Mating Part Yes
Material - Metal Phosphor Bronze
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Polyester Alloy
Net Weight 3.410/g
Number of Rows 1
Packaging Type Bag
Pitch - Mating Interface 2.54mm
Single Ended No
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 1.63mm max.
Wire Size AWG 22
Wire/Cable Type UL 11028

Electrical
Current - Maximum per Contact 3.0A
Voltage - Maximum 600V AC/DC

Material Info

Reference - Drawing Numbers
Sales Drawing 2162701030-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2020)4578-DC (25
June 2020)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[216270 Series](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION