


OA60EC IP68-ATEX Series



EC Fan Universal voltage
60x25mm (2.36"x 1.0")

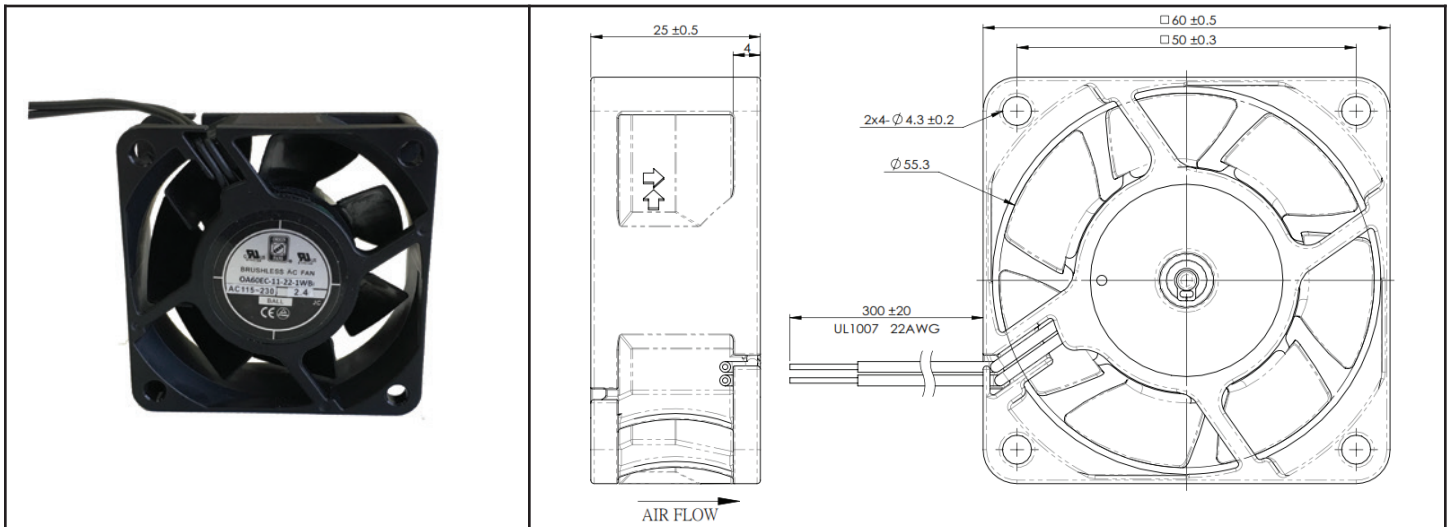

Frame	PBT UL94V-0 Plastic	<p><u>Operating Temperature</u> Ball Bearing -20C ~ +70C</p> <p><u>Life Expectancy</u> Ball Bearing 50,000 hours (L10 at 40C)</p> <p>IP68 Rating with ATEX Certification</p> <p>Weight: ~60 grams</p> <p>Storage Temperature -30C ~ +75C</p> <p>m2</p>	
Impeller	PBT UL94V0- Plastic		
Connection	2 Lead wires		
Motor	Brushless EC motor, electronically protected		
Bearing System	Dual ball		
Insulation Resistance	>10M ohm between lead- wire and frame (500VDC)		
Dielectric Strength	1 sec at 1800 VAC, 50/60Hz		

Part Number	OA60EC-UR-1WBIP68A
Nominal Voltage	95-264 VAC
Rated Power	2.1W/2.4W (115/230VAC)
Locked Rotor Current	0.09/0.05A (115/230VAC)
Frequency (Hz)	50 / 60
Rated Speed (RPM)	3950
Airflow (CFM)	19.5
Noise Level (dB)	31
Max. Static Pressure	0.17"H2O