



**SCHROFF**

 
**PCB cover plates for euroboards, VME**

Catalog Number: 61000-007

- Mechanical protection of solder side
- Suitable for 100 x 160 mm euroboard



Other Views



**Description**

**Mechanics:**

PCB covers and PCB case

**Note:**

The materials of the PCB cover are UL-listed. The test was however conducted with material thickness 1.5 mm

**Type:**

Individual Components

**Individual Component Type:**

Cover Plate

**Standard pack quantity (SPQ):**


Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.



We use cookies to personalize content and ads, to provide social media features and to analyze our traffic. We also share information about your use of our site with our social media, advertising and analytics partners. [Cookie Policy](#)

> [Cookie Settings](#)

✓ [Accept Cookies](#)

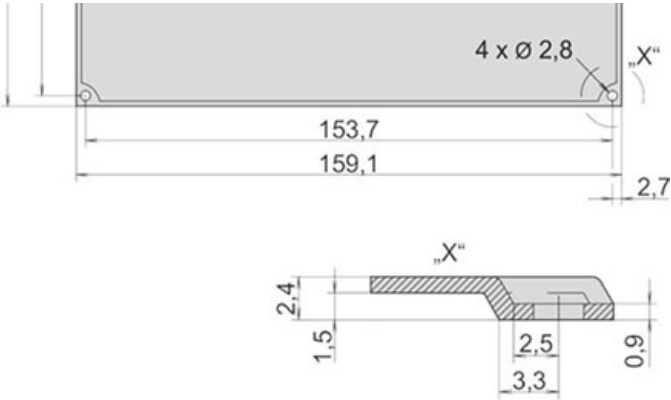

Technical Data

We use cookies to personalize content and ads, to provide social media features and to analyze our traffic. We also share information about your use of our site with our social media, advertising and analytics partners. [Cookie Policy](#)

> [Cookie Settings](#)

✓ [Accept Cookies](#)

Material	LCP, UL 94 V-0
Other	PCB cover (thickness 0.9 mm) for euroboards (100 x 160 mm), PBT, black, max. operating temperature without permanent deformation 55 °C

Documents

We use cookies to personalize content and ads, to provide social media features and to analyze our traffic. We also share information about your use of our site with our social media, advertising and analytics partners. [Cookie Policy](#)

> [Cookie Settings](#)

✓ [Accept Cookies](#)



Native CAD files

Accessories

We use cookies to personalize content and ads, to provide social media features and to analyze our traffic. We also share information about your use of our site with our social media, advertising and analytics partners. [Cookie Policy](#)

> [Cookie Settings](#)

✓ [Accept Cookies](#)



Slotted flathead screw, M2.5 × 12, height of head 1.2 mm,  
PU 100 pieces

21102-008