

L2140	Rated Current A	Leakage Current @ 250V 50Hz	Inductance mH	Connections	Approvals	UL	CSA	SE
L2140/1	1	0.4mA	11.0	6.3 x 0.8 Faston	■	■	■	■
L2140/2	2	0.4mA	3.0	6.3 x 0.8 Faston	■	■	■	■
L2140/3	3	0.4mA	1.3	6.3 x 0.8 Faston	■	■	■	■
L2140/6	6	0.4mA	0.7	6.3 x 0.8 Faston	■	■	■	■
L2140/10	10	0.2mA	0.15	6.3 x 0.8 Faston	■	■	■	■


Temperature Range: -25°C to +85°C
Operating Voltage: 250Vac
Operating Frequency: 0 to 400Hz
Test Voltage: L+N to ground, 2700Vdc, 2 seconds

■ Approved
 □ Submitted for Approval

IEC 950 (EN 60950 Applications)

DIMENSIONS

All dimensions are nominal and in mm

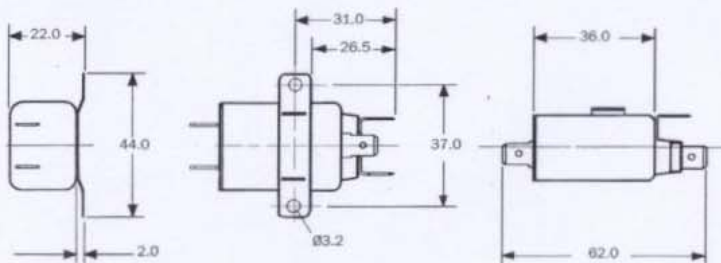

CIRCUIT DIAGRAM

