



PSG3369

HDMI to Scart+Stereo Converter

Please read these instructions carefully before use and retain for future reference.

INTRODUCTION

- The MHL/HDMI to SCART converter which will convert digital MHL/HDMI video and audio signal to composite video signal and the FL / FR stereo audio signal, while support DVI system sideline signals.
- Help users convert the high quality of the HDMI signal and smart Phone MHL signal to normal CVBS signal (standard-definition 480i, 576i,).So that can play on CRT TV, VHS VCR, DVD recorders, etc.
- The MHL/HDMI to SCART converter support NTSC and PAL TV formats output.

FEATURES

- No need to install drivers, portable, flexible, plug and play;
- Support HDMI1.4b Compatible with HDCP;
- Support Input resolution:480i/p,576i/p,720p,1080i/p,4Kx2K@30Hz;
- High quality scaling technology for auto resolutions;
- Support NTSC and PAL two standard TV formats output.
- Share your smart phone photos, music and movies on the TV.

PACKAGE CONTENTS

Before attempting to use this unit please check the packing and make sure the following items are contained in the shipping carton:

- HDMI to Scart Converter-----1Pcs
- 5V DC Power Supply-----1Pcs
- User Manual-----1Pcs

SPECIFICATIONS

- Input port-----1xHDMI
- Output port-----1xSCART, 1x3.5mm Stereo
- Dimensions(mm)-----73(L)x60.5(W)x25(H)
- Wight (g)-----90
- Input Resolution-----640x480@60Hz,800x600@60Hz
1024x768@60Hz,1280x720@60Hz
1280x1024@60Hz,1360x768@60Hz
1600x1200@60Hz,1920x1080@60Hz
480i/60Hz, 480p/60Hz, 576i/60Hz, 576p/60Hz
720p50/60Hz,1080i50/60Hz,1080p23.97/24/25/50/59.94/60Hz
4Kx2K/30Hz
- CVBS output-----PAL,NTSC
- Operating Temperature-----0°C ~ 40°C / 32°F ~ 104°F
- Storage Temperature-----20°C ~ 60°C / -4°F ~ 140°F
- Relative Humidity-----20 ~ 90% RH (Non-condensing)
- Power Consumption (Max)-----2.5W

PANEL DESCRIPTIONS


Please study the panel drawings below and become familiar with the signal input(S),output(S)and power requirements.



- DC 5V -----DC 5V Input
- PWR-----Power indicator
- PAL/NTSC -----PAL and NTSC standard format selector switch
- HDMI Input-----HDMI Input
- Stereo-Out-----earphone Output
- Scart Output -----Scart Output

CONNECTION AND OPERATION

Before installation, please make sure all devices you wish to connect have been turned off.

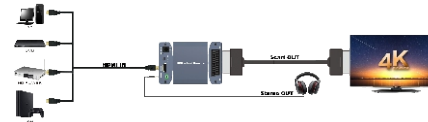

- Connect the HDMI input from source device to this converter. (Input cables are optional)
- Connect the Scart and Stereo audio output of this product to the display device.
- Insert the DC side of 5V power supply into this product and then connect the AC side of the power supply into the wall outlet.
- Power on all connected devices, Choose the input of the display device to its Scart channel.
- The image does not need to be adjusted, the Converter will position it automatically, the user may adjust the horizontal position under some extreme condition.

Attention: Insert / Extract cable gently.

INSTALLATION AND PRECAUTIONS

- When using electrical appliances basic safety precautions should always be followed.
- Check that the voltage indicated on the rating plate corresponds with that of the local network before connecting the PSU to the mains supply.
- Keep the equipment away from moisture or excessive heat.
- There are no user serviceable parts inside.
- Take care when connecting or disconnecting cables.



INFORMATION ON WASTE DISPOSAL FOR CONSUMERS OF ELECTRICAL & ELECTRONIC EQUIPMENT.
When this product has reached the end of its life it must be treated as Waste Electrical & Electronic Equipment (WEEE). Any WEEE marked products must not be mixed with general household waste, but kept separate for the treatment, recovery and recycling of the materials used. Contact your local authority for details of recycling schemes in your area.

Made in China. PR2 9PP
Man Rev 1.0