

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2122092020](#)
Status: **Active**
Overview: CP Wire-to-Board and Wire-to-Wire Connector Systems
Description: CP-3.3 Receptacle Housing, 3.30mm Pitch, Dual Row, Positive Lock, Glow-Wire Capable, 2 Circuits, Natural

Documents:

[Drawing \(PDF\)](#) [Packaging Specification 2122099200-SPK-200 \(PDF\)](#)
[Product Specification 2122090000-PS-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Crimp Housings
Series [212209](#)
Application Power, Wire-to-Board
Overview [CP Wire-to-Board and Wire-to-Wire Connector Systems](#)
Product Name CP-3.3
UPC 193264098972


Physical

Circuits (maximum) 2
Color - Resin Natural
Gender Receptacle
Glow-Wire Capable Yes
Keying to Mating Part Yes
Lock to Mating Part Yes
Material - Resin Polyamide
Net Weight 866.780/mg
Number of Rows 2
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 3.30mm
Pitch - Termination Interface 3.30mm
Polarized to Mating Part Yes
Temperature Range - Operating -40° to +105°C

Material Info

Reference - Drawing Numbers

Packaging Specification 2122099200-SPK-200
Product Specification 2122090000-PS-000
Sales Drawing 2122090000-SD-000

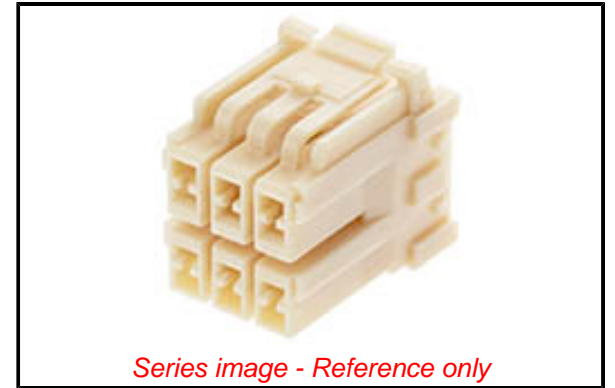

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)4578-DC (25
June 2020)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[212209 Series](#)