

EAO – Your Expert Partner for Human Machine Interfaces

45-2C36.1920.000 - Emergency stop switch - Actuator

45-2C36.1920.000 - Emergency stop switch - Actuator



Attention: The preview is based on a sample product. This can differ from your current configuration.

Attribute

Design	raised
Front form	round
IP front protection	IP66, IP67, IP69K
Mounting cut-out	Ø 22.3 mm
Dimension	Ø 40 mm
Front bezel colour	Black
Front bezel material	Plastic
Front dimension	Ø 40 mm
Housing colour	Yellow
Housing material	Plastic
Lens colour	Red
Lens illumination	non illuminative
Lens material	Plastic
Lens optics	opaque
Lens shape	mushroom-head
Switching action	Maintained
Weight	0.045 kg

Schaltelement

max. number of switching elements	6
-----------------------------------	---

 
Function

Emergency stop switch


EAO – Your Expert Partner for Human Machine Interfaces

45-2C36.1920.000 - Emergency stop switch - Actuator


Dimensions



Mounting cut-outs

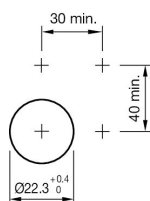

Wiring diagrams

 

Additional information

The standard lock: RONIS, T254

Mounting depth, incl. front plate, see chapter drawings

Application as per DIN EN ISO 13850

Application as per DIN EN ISO 13850 and EN 60204-1

Twist to unlock clockwise