


Part Number: N6590286

Type	Size	Rating	Description
Incandescent	T6	28V 40mA	T-1 <sup>3</sup> / <sub>4</sub> Midget Groove Lamp

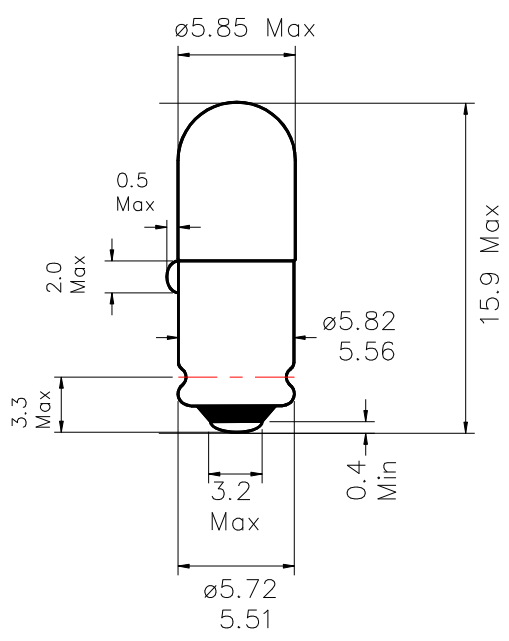

Dimensions in millimetres

TEST VOLTS	CURRENT (mA)			LIGHT OUTPUT (Lm)			LIFE Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
28	36	40	44	2.9	3.8	4.7	10,000

Notes:

- 1 Base Type            Nickel plated S5.7s base in accordance with BS EN 60061-1
- 2 Filament Shape    C-2F
- 3 Lamp Marking      28V 40mA ink stamped on the base
- 4 Environmental      RoHS & REACH SVHC compliant