


Part Number: N9959118

| Type | Size | Rating | Description |
|--------------|------|----------|--------------------------------------|
| Incandescent | T6 | 28V 40mA | T-1 $\frac{3}{4}$ Midget Flange lamp |

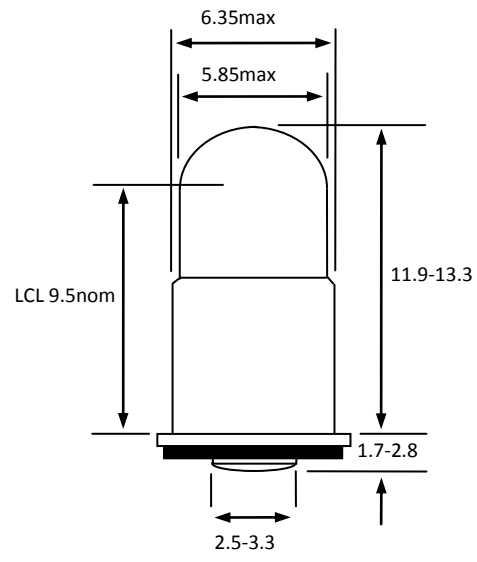

Dimensions in millimetres

| TEST VOLTS | CURRENT (mA) | | | LIGHT OUTPUT (Lm) | | | LIFE Hours |
|------------|--------------|------|------|-------------------|------|------|------------|
| | Min. | Nom. | Max. | Min. | Nom. | Max. | |
| 28 | 36 | 40 | 44 | 3.2 | 4.3 | 5.4 | 4,000 |

Notes:

- 1 **Base Type** SX6s base to EN60061-1
- 2 **Filament Shape** C-2F
- 3 **Lamp Marking** 28V 40mA
- 4 **Environmental** RoHS & REACH SVHC compliant
- 5 **Packaging** Bags of 10 in a carton of 1000