


Part Number: 192DX35X

Type	Size	Rating	Description
LED	M12	24Vac/dc	Standard Bezel Panel Indicator

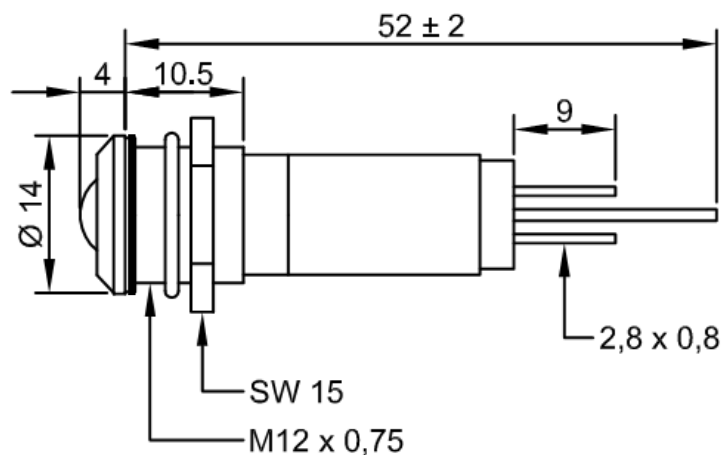

Part #	Colour	Current (mA)	Intensity (mcd)
192DX350	Red	9/17	400
192DX351	Green	9/17	1200
192DX352	Yellow	9/17	350
192DX357	Blue	9/17	450
192DX35WA	White	9/17	2500

## Notes:

- 1 X = Chrome Bezel finish. 0 = Satin, 1 = Black, 2 = Matt
- 2 Electrical & optical data are measured at an ambient temperature of 25°C
- 3 Storage temperature -25 °C to +80°C
- 4 Application temperature -20 °C to +60°C
- 5 Voltage tolerance ±10%
- 6 Due to component tolerances, colour temperature variations may be observed
- 7 The terminals are not qualified for soldering
- 8 Degree of protection IP67 when used with the supplied gasket
- 9 The plastic(polycarbonate) has limited chemical resistance
- 10 RoHS & REACH SVHC compliant