

N-Type Plug to N-Type Plug

multicompPRO


**RoHS
Compliant**



Specifications

Connector to Connector	: N-Type Plug to N-Type Plug
Impedance	: 50Ω
Jacket Colour	: Black

Diagram

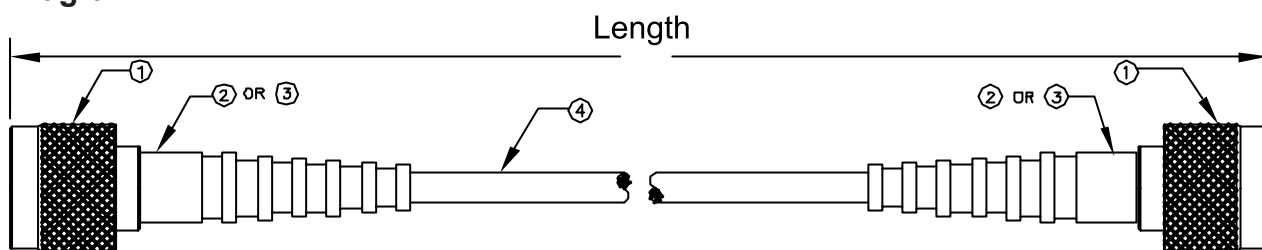

Item	Description	Material	Finish
1	N Male Crimp	Brass	Nickel
2	Strain Relief	Polyvinyl Chloride	Black
3	Tubing	Heat Shrink	Black
4	Cable	-	-

Part Number Table

Description	Strain Relief	Cable Type	Length (Inches)	Part Number
N Male to N Male, Connector assemblies	No	RG-8A/U	12	SPC25331
	No	RG-8A/U	48	SPC25335
	Yes	RG-58C/U	12	SPC25529
	Yes	RG-58C/U	24	SPC25530
	Yes	RG-58C/U	36	SPC25531
	Yes	RG-58C/U	48	SPC25532
	Yes	RG-58C/U	72	SPC25534
	No	RG-214/U	12	SPC25535
	No	RG-214/U	24	SPC25536
	No	RG-214/U	36	SPC25537
	No	RG-214/U	48	SPC25538
	No	RG-214/U	60	SPC25539
	No	RG-214/U	72	SPC25540
	No	RG-188A/U	12	SPC20838
	No	RG-188A/U	24	SPC20839
	No	RG-188A/U	36	SPC25543
	No	RG-188A/U	48	SPC25545

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicompPRO

N-Type Plug to N-Type Plug **multicomp**PRO

Description	Strain Relief	Cable Type	Length (Inches)	Part Number
N Male to N Male, Connector assemblies	No	RG-188A/U	60	SPC25547
	No	RG-188A/U	72	SPC25549
	No	RG-316/U	12	SPC25551
	No	RG-316/U	24	SPC25552
	No	RG-316/U	36	SPC25553
	No	RG-316/U	48	SPC25554
	No	RG-316/U	60	SPC25555
	No	RG-316/U	72	SPC25556
	No	RG-213/U	12	SPC25557
	No	RG-213/U	24	SPC25559
	No	RG-213/U	36	SPC25561
	No	RG-213/U	48	SPC25563
	No	RG-213/U	60	SPC20840
	No	RG-213/U	72	SPC25566
	Yes	RG-58A/U	12	SPC27533
	Yes	RG-58A/U	24	SPC27535
	Yes	RG-58A/U	72	SPC27540
	No	LMR-195	12	SPC27542
	No	LMR-195	24	SPC27543
	No	LMR-195	36	SPC27544
	No	LMR-195	48	SPC27545
	No	LMR-195	60	SPC27546
	No	LMR-195	72	SPC27547
	No	RG-142B/U	12	SPC27548
	No	RG-142B/U	24	SPC27550
	No	RG-142B/U	36	SPC27552
	No	RG-142B/U	48	SPC27554
	No	RG-142B/U	60	SPC20837
	No	RG-142B/U	72	SPC27557
	No	RG-223/U	12	SPC27559
	No	RG-223/U	24	SPC27560
	No	RG-223/U	36	SPC27561
	No	RG-223/U	48	SPC27562
	No	RG-223/U	60	SPC27563
	No	RG-223/U	72	SPC27564
	No	RG-55B/U	12	SPC27565
	No	RG-55B/U	48	SPC27569
	No	RG-55B/U	72	SPC27572

N-Type Plug to N-Type Plug **multicomp**^{PRO}

Description	Strain Relief	Cable Type	Length (Inches)	Part Number
N Male to N Male, Connector assemblies	No	RG-400/U	12	SPC27574
	No	RG-400/U	24	SPC27575
	No	RG-400/U	36	SPC27576
	No	RG-400/U	48	SPC27577
	No	RG-400/U	60	SPC27578
	No	RG-400/U	72	SPC27579
	No	BELDEN9913	12	SPC27580
	No	BELDEN9913	24	SPC27581
	No	BELDEN9913	36	SPC27582
	No	BELDEN9913	48	SPC27583
	No	BELDEN9913	60	SPC27584
	No	BELDEN9913	72	SPC27585
	No	LMR-400	12	SPC27586
	No	LMR-400	24	SPC27587
	No	LMR-400	36	SPC27588
	No	LMR-400	48	SPC27589
	No	LMR-400	60	SPC27590
	No	LMR-400	72	SPC27591
	No	RG-8/X	12	SPC27592
	No	RG-8/X	24	SPC27593
	No	RG-8/X	36	SPC27594
	No	RG-8/X	48	SPC27595
	No	RG-8/X	60	SPC27596
	No	RG-8/X	72	SPC27597
	No	LMR-240	12	SPC27598
	No	LMR-240	24	SPC27599
	No	LMR-240	36	SPC27600
	No	LMR-240	48	SPC27601
	No	LMR-240	60	SPC27602
	No	LMR-240	72	SPC27603
	No	LMR-600	12	SPC27604
	No	LMR-600	24	SPC27605
	No	LMR-600	36	SPC27606
	No	LMR-600	48	SPC27607
	No	LMR-600	60	SPC27608
	No	LMR-600	72	SPC27609
	No	LMR-200	12	SPC27610
	No	LMR-200	24	SPC27611

N-Type Plug to N-Type Plug multicomp^{PRO}

Description	Strain Relief	Cable Type	Length (Inches)	Part Number
N Male to N Male, Connector assemblies	No	LMR-200	36	SPC27612
	No	LMR-200	48	SPC27613
	No	LMR-200	60	SPC27614
	No	LMR-200	72	SPC27615
	No	LMR-600-ULTRA-FLEX	12	SPC29115
	No	LMR-600-ULTRA-FLEX	24	SPC29116
	No	LMR-600-ULTRA-FLEX	36	SPC29117
	No	LMR-600-ULTRA-FLEX	48	SPC29118
	No	LMR-600-ULTRA-FLEX	60	SPC29119
	No	LMR-600-ULTRA-FLEX	72	SPC29120

Important Notice : This data sheet and its contents (the "Information") belong to the members of the AVNET group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. Multicomp Pro is the registered trademark of Premier Farnell Limited 2019.

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp^{PRO}