

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **2125153101**
Status: **Active**
Overview: Mini-Fit Family Power Connectors
Description: Mini-Fit Max Female Crimp Terminal, Tin over Nickel Plating, 14 AWG, Reel

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification 2125150001-PK-000 \(PDF\)](#)

General

Product Family	Crimp Terminals
Series	<u>212515</u>
Application	Power, Wire-to-Board, Wire-to-Wire
Crimp Quality Equipment	Yes
Overview	<u>Mini-Fit Family Power Connectors</u>
Product Name	Mini-Fit Max
UPC	193264598304

Physical

Durability (mating cycles max)	30
Gender	Female
Material - Metal	High Conductivity Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.330/g
Packaging Type	Reel
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	2.78mm Max.
Wire Size AWG	14
Wire Size mm ²	N/A


Electrical

Voltage - Maximum	600V
-------------------	------

Material Info

Reference - Drawing Numbers

Packaging Specification	2125150001-PK-000
Sales Drawing	2125150001-SD-000

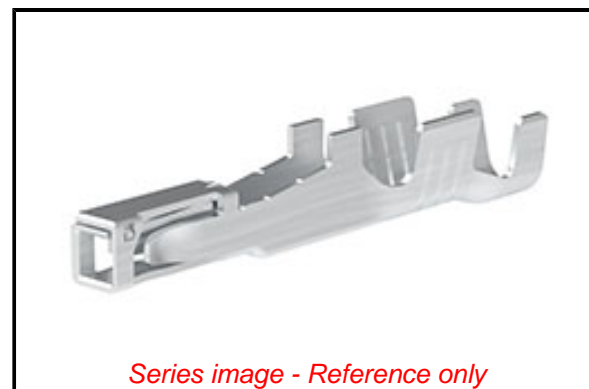

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

212515 Series

Use With

Mini-Fit Max Crimp Housing 212514

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
FineAdjust Applicator for Mini-Fit MAX Receptacle Crimp Terminal, 14 AWG (UL1007/UL1569) Wire	<u>2037026500</u>
Extraction and Activation Tool	<u>638132700</u>

This document was generated on 03/02/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION