

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2125141002

Status:


Active

Overview:

Mini-Fit Family Power Connectors

Description:

Mini-Fit Max Receptacle Housing, Dual Row, UL 94V-0, 2 Circuits, Glow-Wire Capable, Black

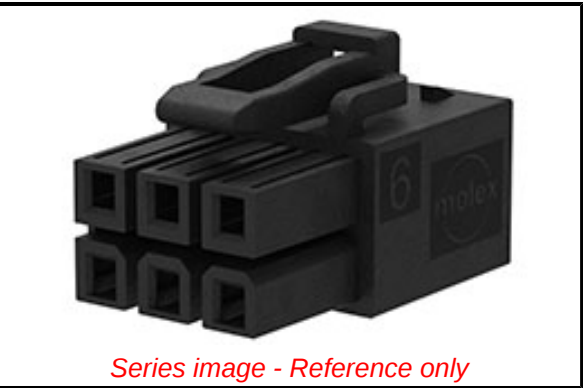

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	212514
Application	Power, Wire-to-Board, Wire-to-Wire
Overview	Mini-Fit Family Power Connectors
Product Name	Mini-Fit Max
UPC	193264598243
Physical	
Circuits (maximum)	2
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	Yes
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	0.940/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	4.20mm
Pitch - Termination Interface	4.20mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C
Material Info	
Reference - Drawing Numbers	
Sales Drawing	2125140001-SD-000

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2020)9139-DC (19 Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

212514 Series

Mates With

Mini-Fit Max Header [212520](#)

Use With

Mini-Fit Max Crimp Terminal [212515](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION